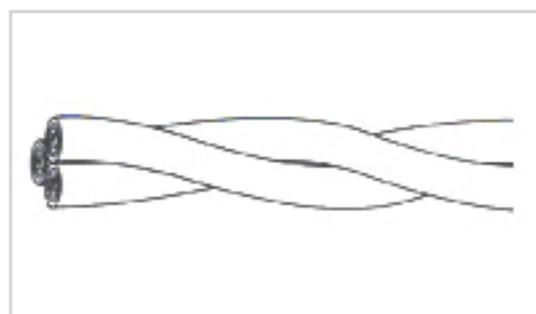


55K9083-20-2/6/4 Product Details

[Share](#) [Print](#) [Email](#) Active

Spec 44, Spec 55 and Spec RCW Wire and Cable

55K9083-20-2/6/4

55K9083-20-2/6/4 

TE Internal Number: 7490293001

[Pricing & Availability](#) [Request Sample](#) [Add to My Part List](#) [Buy Product through
Distributor](#) 

[+] Feedback

[Documents](#) [Features](#) [Compliance](#)**Please Note:**
Use the Product Drawing for all design activity **Product Type Features**

Cable Type 	Spec 55
Cable Style	Special Construction

Electrical Characteristics

Voltage Rating (VAC)	600
----------------------	-----

Body Features

Wire Size (AWG/CM)	20 AWG
Conductor Type	Nickel-Coated Copper
Wire Color	Red, Blue, Yellow
Nominal Outside Diameter (mm [in])	3.02 [0.119]
Wire Diameter (mm [in])	1.40 [0.055]

Configuration Features

Number of Conductors	3
----------------------	---

Industry Standards

Government/Industry Qualification	No
RoHS/ELV Compliance 	RoHS compliant, ELV compliant
Lead Free Solder Processes 	Not relevant for lead free process
RoHS/ELV Compliance History	Always was RoHS compliant

Conditions for Usage

Temperature Range (°C)	-65 – +200
------------------------	------------

Operation/Application

Application	General Purpose
-------------	-----------------

Packaging Features

Wire Source	United Kingdom
-------------	----------------

Other

Brand	Raychem
-------	---------

Related Products

Not quite the product you're looking for?

[Find Similar Products](#)[View Part in Product Feature Selector](#)[Check for Tooling](#)**Corporate Information**[About TE](#)[Investors](#)[News Room](#)[Supplier Portal](#)[Careers](#)[Terms & Conditions](#)[Privacy Policy](#)[Global Accessibility Statement](#)**Quick Links**[Distributor Inventory](#)[Product Cross Reference](#)[Documents & Drawings](#)[Product Compliance Support Center](#)[Site Map](#)**Customer Support**[Email or Chat With Us](#)[Find a Phone Number](#)[Knowledge Base](#)[Manage Your Account](#)**Keep Me Informed**