


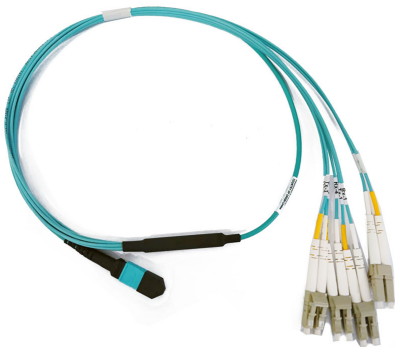

Part Number : [885366503](#)
Product Description : MPO QSFP-to-4 LC Duplex Fiber Optic Breakout Plenum Cable Assembly, High Bandwidth (OM3), Multimode, Bare Fiber Interconnect Plenum Cable, 3.0m Length
Series Number : 88536
Status : Active
Product Category : Fiber Optic Cable Assemblies



Documents & Resources

Drawings
[885366503_sd.pdf](#)

Specifications
[885366203-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2024)7663-DC (21 Jan 2025)
EU RoHS	Compliant with Exemption 6(c) per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D

- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Fiber Optic Cable Assemblies
Series	88536
Description	MPO QSFP-to-4 LC Duplex Fiber Optic Breakout Plenum Cable Assembly, High Bandwidth (OM3), Multimode, Bare Fiber Interconnect Plenum Cable, 3.0m Length
Connector to Connector	MPO-to-LCD
Mode	Multimode
Product Name	MPO,QSFP
UPC	195842246911

Physical

Boot Type	Straight
Cable Length	3.0m
Cable Size	3.00mm
Fiber (Core/Cladding)	50/125µm OM3
Net Weight	75.000/g
Single Ended	No
Wire/Cable Type	Bare Fiber Interconnect, Plenum

This document was generated on Apr 19, 2025
