




CT50400M, Cable Tie, 4" Max Bundle, 50 Lb Tensile, Natural

By Burndy
Catalog # [CT50400M](#)

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength, Natural,
Nylon 6/6, 15.5" Long, 1000 pack

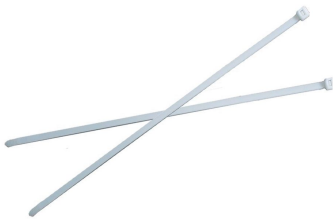

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application

For General Purpose

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	Military Specified (Mil-Spec)
Military Spec Number	MS3367-2-9
Certification - ETL	No
Standards - Industry Standards Met	Military Specified (Mil-Spec)
Standards - RoHS Compliance Status	CM
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Dimension - L Length Overall mm	362 mm
Width	0.18 in
Length	15.5 in
Dimension - Width mm	5 mm
Dimension - Width inch	0.18 in

Dimension - Length Overall inch	14.25 in
Dimension - Bundle Diameter Max inch	4

Force Related

Rating - Minimum Tensile Strength lbs	50
---------------------------------------	----

General

Trade Name	UNIRAP™
Military Specification	MS3367
Color	Natural
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
UPC	781810332795
Type	Standard
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810332795

Logistics

Minimum Pack Quantity	1000
Carton Quantity	5000

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)