


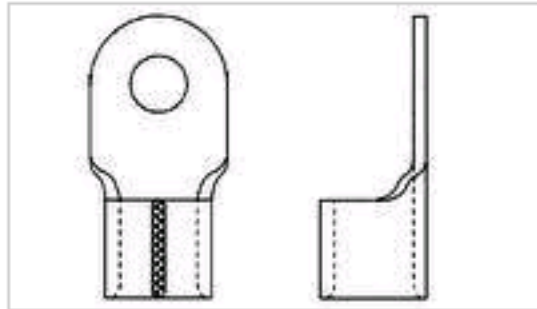

135536-1 Product Details

[Share](#) [Print](#) [Email](#)


✓ Active

Ring and Spade Tongue Terminals

TERMINAL SOLISTRAND 3/0

135536-1 

TE Internal Number: 135536-1

Product Highlights [View All](#)

- Terminal Shape = Ring Tongue
- Receptacle Style = Bent 90 Degrees
- Body Style = SOLISTRAND
- Barrel Type = Closed Barrel
- Wire/Cable Type = Solid/Stranded

[Pricing & Availability](#)
[Request Sample](#)
[Add to My Part List](#)
[Buy Product through Distributor](#)
[Feedback](#)
[Documents](#)
[Features](#)
[Compliance](#)

Please Note:

Use the Product Drawing for all design activity

Product Type Features

Receptacle Style  Bent 90 Degrees

Barrel Type  Closed Barrel

Wire/Cable Type Solid/Stranded

Insulation  No

Insulation Support  Non-Insulation Support

Heavy Duty  No

Finish  Nickel

Dimensions

Stud Diameter (mm [in])  10.50 [0.413]

Length (mm [in]) 53.65 [2.112]

Width (mm [in]) 25.40 [1.000]

Body Features

Body Style  SOLISTRAND

Wire Range (mm [AWG])  10.40² [3/0]

Material  Copper

Contact Features

Terminal Shape  Ring Tongue

Industry Standards

Government/Industry Qualification No

RoHS/ELV Compliance  RoHS compliant, ELV compliant

Lead Free Solder Processes  Not relevant for lead free process

RoHS/ELV Compliance History Always was RoHS compliant

Packaging Features

Packaging Method Box

Packaging Quantity 100

Other

Brand TE Connectivity

Related Products

Not quite the product you're looking for?

[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

Corporate Information

[About TE](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)
[Terms & Conditions](#)
[Privacy Policy](#)
[Global Accessibility Statement](#)

Quick Links

[Distributor Inventory](#)
[Product Cross Reference](#)
[Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

Customer Support

[Email or Chat With Us](#)
[Find a Phone Number](#)
[Knowledge Base](#)
[Manage Your Account](#)

Keep Me Informed

