


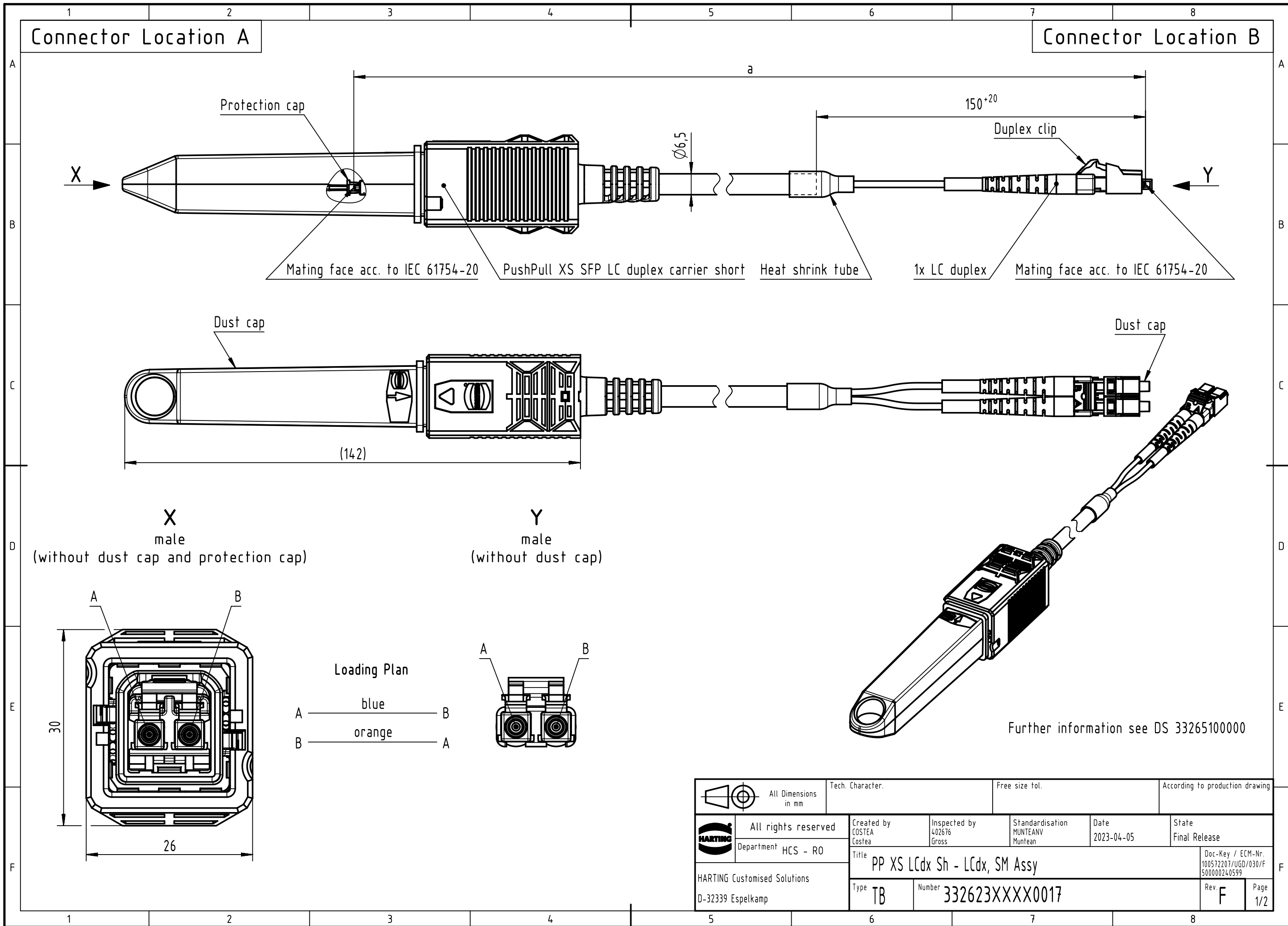

	1	2	3	4	5	6	7	8
A								
B								
C	28	33262311000017	FO Cable, 2-channel, SM, 9/125µm, PUR, black	100	±1%			
	27	33262310900017		90				
	26	33262310800017		80				
	25	33262310700017		70				
	24	33262310600017		60				
	23	33262310500017		50				
	22	33262310450017		45				
	21	33262310400017		40				
	20	33262310350017		35				
	19	33262310300017		30				
D	18	33262310250017		25				
	17	33262310200017		20				
	16	33262310150017		15				
	15	33262310140017		14				
	14	33262310130017		13				
	13	33262310120017		12				
	12	33262310110017		11				
E	11	33262310100017		10	±0.03			
	10	33262310090017		9				
	9	33262310080017		8				
	8	33262310070017		7				
	7	33262310060017		6				
	6	33262310050017		5				
	5	33262310040017		4				
F	4	33262310030017		3				
	3	33262310020017		2				
	2	33262310010017		1				
	1	33262330500017		0.5				
	Cont. no.	Part no.	Type of cable	Dim. a[m]				



All rights reserved

Department HCS - RO

All Dimensions in mm

Tech. Character.

Free size tol.

According to production drawing

Created by
COSTEA
Costea

Inspected by
402676
Gross

Standardisation
MUNTEANV
Muntean

Date
2023-04-05

State
Final Release

Title
PP XS LCdx Sh - LCdx, SM Assy

Doc-Key / ECM-Nr.
100572207/UGD/030/F
500000240599

HARTING Customised Solutions
D-32339 Espelkamp

Type
TB

Number
332623XXXX0017

Rev.
F

Page
2/2