


RoHS
Compliant

VERSION	DESCRIPTION	DATE
1.0	New Release	2018/4/12

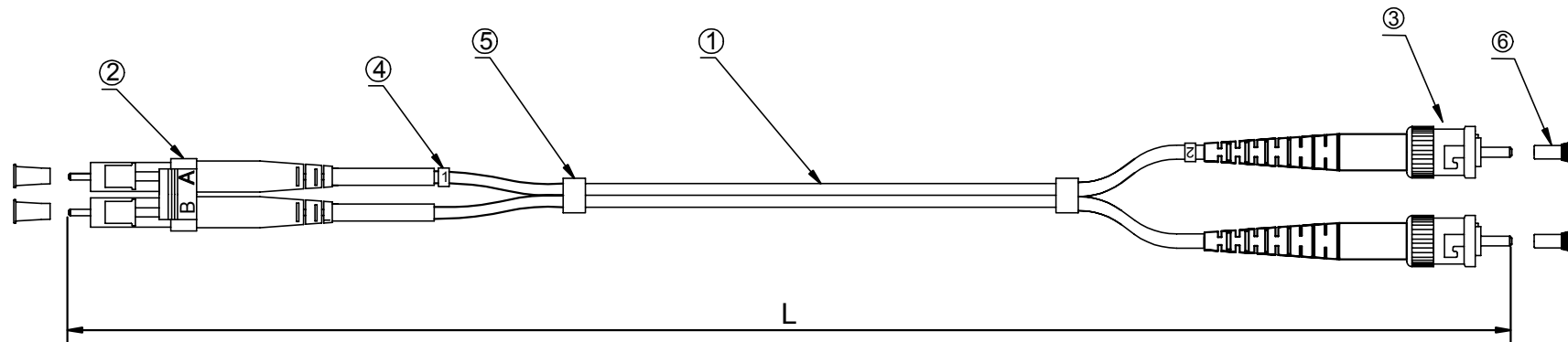

PART NO	DRAWING NO	CABLE LENGTH "L"	COLOR
913S-2-5-00100	671-461-A	1000±100	Yellow
913S-2-5-00200	671-461-B	2000±100	Yellow
913S-2-5-00300	671-461-C	3000±100	Yellow
913S-2-5-00500	671-461-D	5000±100	Yellow
913S-2-5-00700	671-461-E	7000±100	Yellow
913S-2-5-01000	671-461-F	10000±100	Yellow
913S-2-5-01500	671-461-G	15000±100	Yellow
913S-2-5-02000	671-461-H	20000±100	Yellow
913S-2-5-02500	671-461-I	25000±100	Yellow

NOTES:

Insertion loss < 0.3 dB
Return loss > 50 dB

6	Dust Cover
5	Shrinkage Tube
4	$\frac{1}{2}$ Code
3	ST SM Connector (Metal housing Yellow boot)
2	LC SM Duplex Connector (Blue housing White boot)
1	2.0mm,Duplex,SM-9/125 G652D, PVC, Optical Fiber Cable(Yellow)
No.	Description

CnC Tech, LLC Industrial Cable and Connector Technology					
		TITLE		Patch Cord, LC-ST,SM-9/125 G652D, Duplex, PVC, yellow, 2.0mm, xxM	
UNIT		P/N		DRAWN BY	
unless otherwise stated mm Tolerances XXX.XX ±0.3 XX.XX ±0.2 X.XX ±0.1		Customer P/N		CHECK BY	
SIZE A4		SCALE Free		PAGE	1/1
				APPROVAL BY	