


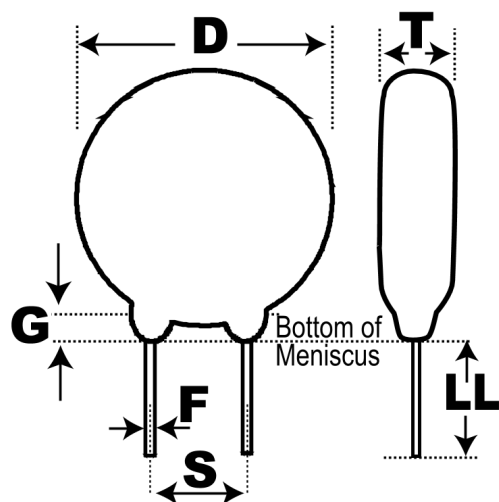

General Information

Series	KHA
Style	Radial Disc
RoHS	Yes
Termination	Tin
Failure Rate	N/A
AEC-Q200	No
Miscellaneous	Climate Category: 55/125/21.

Specifications

Capacitance	1000 pF
Capacitance Tolerance	10%
Voltage DC	1000 VDC
Dielectric Withstanding Voltage	2000 VDC
Temperature Range	-55/+125°C
Temperature Coefficient	X7R
Dissipation Factor	2.5%
Insulation Resistance	10 GOhms

Dimensions

D	7.5mm MAX
T	4.5mm MAX
S	5mm NOM
F	0.6mm +/-0.1mm

Packaging Specifications

Packaging	Ammo, 340x250x50mm Box, H0 = 16mm, Component Pitch = 12.7mm
Packaging Quantity	1000