

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1210230466

Status:


Active

Overview:

mPm DIN Valve Connectors

Description:

mPm DIN Valve Connector, Form C-Micro 9.4mm, PG7 Internal Threads, 3 Pole Plus Ground Terminal, 250V AC/300V DC, Black, Nitrile Profiled Gasket and Screw, Bulk Pack Mounted

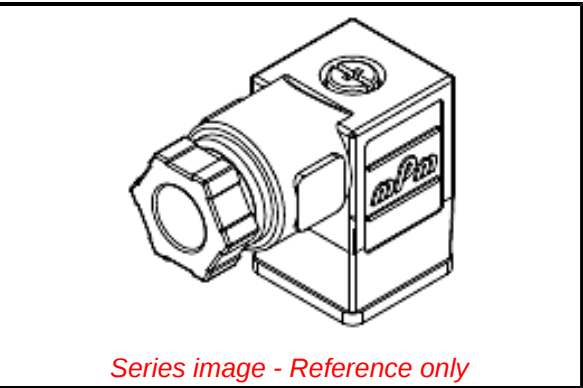

Documents:

[Drawing \(PDF\)](#)

[Packaging Specification PK-121023-C19-001 \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family

Series

Form

IP Rating

Material - Contact

Overview

Product Name

Type

UPC

Field Attachable / Accessories

121023

C - Micro 9.4mm

IP65, IP67

Brass

mPm DIN Valve Connectors

mPm

Field Attachable Connector

883906249083

Physical

Cable Diameter

Coupling Type

Diagnostics / LEDs

Diagnostics Port

Gender

Keyway

Material - Connector Body

Material - Coupling Nut

Material - Plating Mating

Orientation

Pitch - Mating Interface

Poles

Temperature Range - Operating

Wire Size AWG

N/A

Internal Thread

No

No

N/A

None

Polypropylene

N/A

Silver

90° Angle

9.40mm

3

-40°C to +90°C

N/A

Electrical

Current - Maximum per Contact

Voltage - Maximum

16.0A

250V AC / 300V DC

Material Info

Engineering Number

C19307N61

Reference - Drawing Numbers

Packaging Specification

Sales Drawing

PK-121023-C19-001

SD-121023-005-001

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2022)4187-DC (10 June 2022)

Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

50 Image

Not Relevant

Not Contained

Search Parts in this Series

121023 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION