


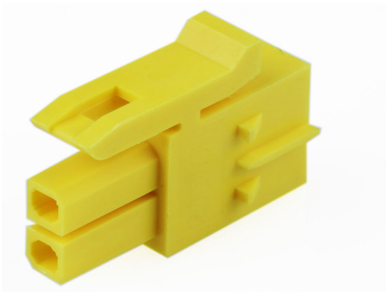

**Part Number :** [2064610204](#)  
**Product Description :** Micro-Fit+ Versa Color Receptacle Housing, Dual Row, 2 Circuits, UL 94V-0, Glow-Wire Capable, Yellow  
**Series Number :** 206461  
**Status :** Active  
**Product Category :** Connector Housings



## Documents & Resources

### Drawings

[2064610204\\_sd.pdf](#)  
[2064610000-PK-000.pdf](#)

### 3D Models and Design Files


[2064610204\\_stp.zip](#)

### Specifications

[2064600001-AS-000.pdf](#)  
[2064600000-PS-000.pdf](#)  
[2159530000-PS-000.pdf](#)  
[2064600000-TS-000.pdf](#)  
[2064600001-TS-000.pdf](#)  
[2159530000-TS-000.pdf](#)

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

### Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC

- Low-Halogen

## Multiple Part Industry Compliance Documents

- IPC 1752A Class C

- IPC 1752A Class D

- Molex Product Compliance Declaration

- IEC-62474

- chemSHERPA (xml)

## EU RoHS Certificate of Compliance

---

### Part Details

#### General

Status	Active
Category	Connector Housings
Series	206461
Description	Micro-Fit+ Versa Color Receptacle Housing, Dual Row, 2 Circuits, UL 94V-0, Glow-Wire Capable, Yellow
Application	Power, Wire-to-Board, Wire-to-Wire
Product Name	Micro-Fit+ Versa Color
UPC	196823363030

#### Agency

UL	E29179
----	--------

#### Physical

Circuits (maximum)	2
Color - Resin	Yellow
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	Yes
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	0.347/g
Number of Rows	2
Packaging Type	Bag

Panel Mount	No
Pitch - Mating Interface	3.00mm
Pitch - Termination Interface	3.00mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +125°C

---

## Mates With / Use With

### Mates with Part(s)

Description	Part Number
Micro-Fit+ Vertical, Dual Row, Through Hole Headers	<u>206832</u>
Micro-Fit+ Right-Angle, Dual Row, Through Hole Headers	<u>212528</u>
Micro-Fit+ Dual Row Surface Mount Headers	<u>218216</u>
Micro-Fit+ Versa Color Vertical, Dual Row, Through Hole Headers	<u>224246</u>
Micro-Fit+ Dual Row Plug Housings	<u>215922</u>

### Use with Part(s)

Description	Part Number
Micro-Fit+ Female Crimp Terminals	<u>206460</u>
Micro-Fit+ Terminal Position Assurance (TPA) Retainers	<u>206462</u>

---

This document was generated on Mar 05, 2025