

Part Number : [1300940227](#)


Product Description : Standard Duty Support Grip, Double Eye, Closed Mesh, Double Weave, Cable Diameter 76.20-88.65mm (3.000-3.490"), Approximate Break Strength 2394.97kg (5280 lbs)

Series Number : 130094

Status : Active

Product Category : Cable Grips

Engineering Part Number : 35010

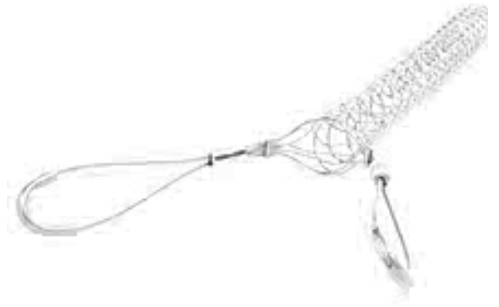

Documents and Resources

Drawings

[PK-130227-004-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Reviewed per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Not Reviewed per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Cable Grips
Series	130094
Description	Standard Duty Support Grip, Double Eye, Closed Mesh, Double Weave, Cable Diameter 76.20-88.65mm (3.000-3.490"), Approximate Break Strength 2394.97kg (5280 lbs)
Product Name	Standard Duty
Type	Support Grip
UPC	78678835010

Agency

CSA	LR32159
-----	---------

Physical

Approximate Break Strength	2394.97kg (5280 lbs)
Bale Length	0.203m (8.00")
Body Style	Straight
Cable Diameter	76.20-88.65mm (3.000-3.490")
Color - Grommet	N/A
Eye Type	Double
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.66m (26.00")
Net Weight	1.000/g
Number of Holes	N/A

O-Ring	N/A
Thread Size	N/A

This document was generated on May 20, 2026