


# PX0844/A3/0M50/A3 Datasheet

 [View Product Page](#)

**Product Name // Front Panel Mount USB 3.0 Extension**  
**Cable PX0844 Series Sealed A Socket Front of Panel to**  
**Standard A Plug 0.5M Cable**

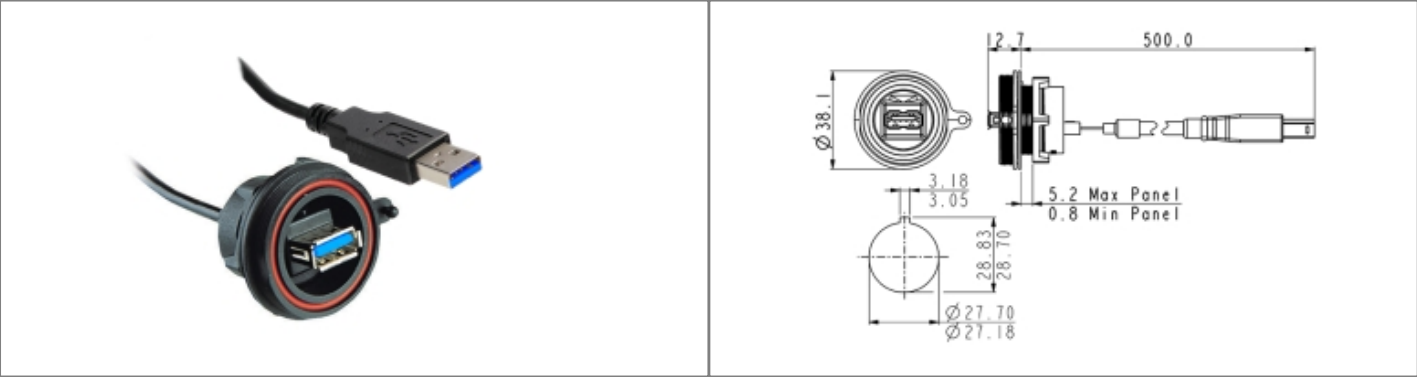

**// Product Description:**

- Front Panel Mount USB Extension
- Water and dustproof to IP68 when mated with compatible connector
- Sealed Standard USB 3.0 Type A socket to 500mm long cable terminated in Standard USB 3.0 Type A plug
- PX0733 Sealing Cap available separately to maintain IP rating of unmated connectors
- Mate with PX0840, PX0841 USB Cables

**// General Information:**

Product Family:	Circular Data Connectors
Product Series:	Standard Buccaneer - USB
Body Colour:	Black
Body Material:	Polyester (PE) - Glass Filled
Body Material Type:	Plastic Body
Cable Length:	0.5m
Contact Type:	Socket Contact
Coupling Type:	Screw
Current Max:	1A
Data Cable Type:	USB 3.0 Sealed A Socket to Standard A Plug
Diameter Over Coupling Ring Mm:	38.1mm
Flamability Rating:	UL94V-0
Function:	Front Panel Mount Connector
Ip Rating:	IP68, IP69K
Max Operating Temperature:	+70°C
Min Operating Temperature:	0°C
Number Of Contacts:	9 Contacts
Rohs Compliant:	Yes
Voltage Max:	5V

**// Product PDF Links**

 [Standard Series USB connectors...](#)

**// Product 3D CAD Model Links**

 [PX0844/A3/0M50/A33D CAD Model](#)