

**SCHROFF**

Project - 0 item(s)

MY PROJECT LIST

PRODUCTS

APPLICATIONS

INDUSTRIES

NEW PRODUCTS

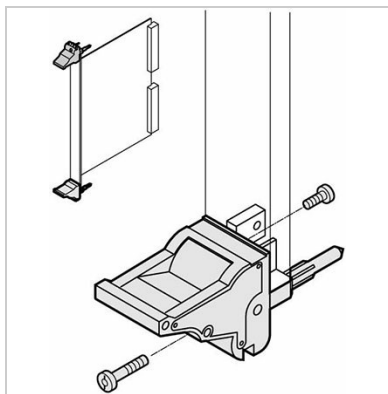
CONFIGURATORS

Products ▾

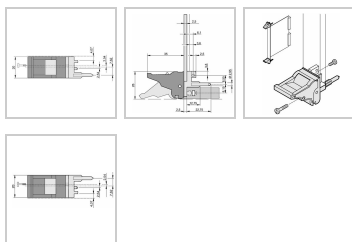
Search

Home > [Inserter/extractor handle, type IEL, grey, bottom \(Rear I/O 6 U top\)](#)

Inserter/extractor handle, type IEL, grey, bottom (Rear I/O 6 U top)

SCHROFF

Other Views

**Catalog Number: 20817-620**[Back To Product](#)

- with integrated alignment pin for perforated strip
- block die-cast zinc, nickel plated
- suitable for fitting of microswitches
- lever/key UL 94 V-0
- codable to IEEE 1101.10 and IEC 60297-3-103
- slotted Pozidrive collar screw, M2.5 x 12.3, St, nickel-plated
- in accordance with IEEE 1101.10 and IEC 60297-3-102
- panhead screw with Torx, M2.5 x 7, St, nickel-plated
- suitable for insertion and extraction forces up to 700 N (per pair)
- with locking

Specification:

- IEC 60297-3-103
- IEEE 1101.10
- IEC 60297-3-102

Handle:

IEL

Type:

Individual Components

Standard:

- CompactPCI
- VME64x

Individual Component Type:

Handle

Delivery Includes:

assembled

Product family:

Plug-in units

**Select product specifications before modifying or adding to project list or requesting a quote.**

Version-defining

Bottom ▾

Qty-defining

10 ▾

[Clear Selection](#)Quantity

Modify Product ►

Add Item to Project List +

Documents

Main Catalog - Plug-in units



User manual, coding IEEE

Links

Native CAD files

Technical Data

 
 
Qty	PU 10 pieces
Material	Plastic Lever, die-cast zinc base, UL 94 V-0
Finish	Lever: light grey, RAL 7035; Key: black, RAL 9005
Configuration	3 U Bottom Front / 6 U Top Rear I/O / 6 U Bottom

Delivery Comprises:

Item	Quantity	Description
1	1	Zn die-cast with integrated alignment pin for perforated strip and IEEE 1101.10 guide rail
2	1	Lever, plastic PC, UL 94 V-0
3	1	Key, plastic PC, UL 94 V-0
4	1	Pozidrive collar screw, M2.5 × 12.3, St, nickel-plated
5	1	Pan head screw with Torx, M2.5 × 7, St, nickel-plated

Accessories

	Front panel (3 U 11 HP), U profile, EMC shielding textile gasket, for IEL/IET/Trapeziform Type 2 handle	20848-228	Add Item to Project List +
	Front panel (3 U 9 HP), U profile, EMC shielding textile gasket, for IEL/IET/Trapeziform Type 2 handle	20848-227	Add Item to Project List +
	Front panel (3 U 16 HP), U profile, EMC shielding textile gasket, for IEL/IET/Trapeziform Type 2 handle	20848-232	Add Item to Project List +
	Front panel (3 U 14 HP), U profile, EMC shielding textile gasket, for IEL/IET/Trapeziform Type 2 handle	20848-230	Add Item to Project List +
	Front panel (3 U 5 HP), U profile, EMC shielding textile gasket, for IEL/IET/Trapeziform Type 2 handle	30848-300	Add Item to Project List +
	Front panel (3 U 7 HP), U profile, EMC shielding textile gasket, for IEL/IET/Trapeziform Type 2 handle	30848-301	Add Item to Project List +
	Front panel (3U 4HP), U profile, EMC shielding textile gasket, for IEL/IET/Trapeziform Type 2 handle, 1pcs (SPQ 5)	30848-312	Add Item to Project List +
	Front panel (3U 4HP), U profile, EMC shielding textile gasket, for IEL/IET/Trapeziform Type 2 handle, 1pcs (SPQ 5)	30848-313	Add Item to Project List +
	Front panel (3U 4HP), U profile, EMC shielding textile gasket, for IEL/IET/Trapeziform Type 2 handle, 1pcs (SPQ 5)	30848-314	Add Item to Project List +

	Front panel (3U 4HP), U profile, EMC shielding textile gasket, for IEL/IET/Trapeziform Type 2 handle, 1pcs (SPQ 5)	30848-315	Add Item to Project List +
	Front panel (3U 4HP), U profile, EMC shielding textile gasket, for IEL/IET/Trapeziform Type 2 handle, 1pcs (SPQ 5)	30848-316	Add Item to Project List +
	Front panel (3U 4HP), U profile, EMC shielding textile gasket, for IEL/IET/Trapeziform Type 2 handle, 1pcs (SPQ 5)	30848-327	Add Item to Project List +
	Front panel (3U 4HP), U profile, EMC shielding textile gasket, for IEL/IET/Trapeziform Type 2 handle, 1pcs (SPQ 5)	30848-328	Add Item to Project List +
	Front panel (3U 4HP), U profile, EMC shielding textile gasket, for IEL/IET/Trapeziform Type 2 handle, 1pcs (SPQ 5)	30848-329	Add Item to Project List +
	Front panel (3U 4HP), U profile, EMC shielding textile gasket, for IEL/IET/Trapeziform Type 2 handle, 1pcs (SPQ 5)	30848-330	Add Item to Project List +
	Front panel (3U 4HP), U profile, EMC shielding textile gasket, for IEL/IET/Trapeziform Type 2 handle, 1pcs (SPQ 5)	30848-331	Add Item to Project List +
	Front panel (3U 4HP), U profile, EMC shielding textile gasket, for IEL/IET/Trapeziform Type 2 handle, 1pcs (SPQ 5)	30848-333	Add Item to Project List +
	Front panel (3U 4HP), U profile, EMC shielding textile gasket, for IEL/IET/Trapeziform Type 2 handle, 1pcs (SPQ 5)	30848-335	Add Item to Project List +
	Label strips for IEL/IET handle, white, sheet with 210pcs (19x9,5), PU 1 pcs	60817-340	Add Item to Project List +
	Label strips for IEL handle, white, sheet with 320pcs (19x4,8), PU 1 pcs	60817-341	Add Item to Project List +
	Microswitch for IEL/IET handle, PU 10 pcs	20817-606	Add Item to Project List +

[News & Events](#)

[Newsletter Subscriptions](#)

[Strategic Partnerships](#)

[Investor Relations](#)

[Global Locations](#)

[Product Compliance & Certifications](#)

[Partner Login](#)

[Videos](#)

[Product Configurators](#)

[Warranties and Terms of Sale & Procurement](#)

© 2018 nVent. All rights reserved | [Privacy Policy](#) | [Terms of Use](#) | [Cookie Policy](#) | [Imprint](#) | [Site Map](#)

Connect With Us

