

- Home
- Custom Wall Plates
- Custom Panels
- Custom Enclosures
- Custom Rack Mount
- Custom Cables
- Machining Services
- Design & Engineering Services
- Value Added Services
- Pelican Case Panels
- Pelican Case Services
- Storm Case Panels
- Nanuk Case Panels
- Seahorse Case Panels
- Pelican, Storm, Nanuk & Seahorse Cases
- Wall Plates & Panels
- Enclosures
- Panel-Mount Cables
- Panel-Mount Couplers
- Rugged Cables
- Dust Covers
- Accessories & Hardware
- USB Cables
- Video Cables
 - VGA Cables
 - DVI Cables
 - HDMI Cables
 - DisplayPort Cables
 - SCART Cables
 - Analog Video
 - Video Electronics
- Serial & Parallel
- Audio Cables
- Power Cables
- Networking
- FireWire Cables
- Fiber Optic
- SCSI
- PS/2
- Other Data Cables
- Manual Switches
- Wireless Products
- Clearance & Specials
- Contact Us
- Support
- Order Status
- Tech Info
 - USB Info
 - USB 3 Info
 - USB-C Info

DisplayPort Panel-Mount Extension

Categories:

> [DisplayPort Cables](#), [Digital Video Panel-Mount Cables](#)

DataPro's DisplayPort Panel-Mount extension cables are the perfect solution for next-generation high-resolution video and audio. Now you can directly access HDTV equipment through walls or cabinets, with no on-site termination or hassle.



DataPro

1170-01E	DisplayPort Panel-Mount Ext.	1 ft	1630 in stock	+ Add to cart
1170-02E	DisplayPort Panel-Mount Ext.	2 ft	2204 in stock	+ Add to cart
1170-03C	DisplayPort Panel-Mount Ext.	3 ft	621 in stock	+ Add to cart
1170-04E	DisplayPort Panel-Mount Ext.	4 ft	334 in stock	+ Add to cart
1170-06E	DisplayPort Panel-Mount Ext.	6 ft	387 in stock	+ Add to cart
1170-10E	DisplayPort Panel-Mount Ext.	10 ft	231 in stock	+ Add to cart
1170-15C	DisplayPort Panel-Mount Ext.	15 ft	279 in stock	+ Add to cart
1170-25E	DisplayPort Panel-Mount Ext.	25 ft	69 in stock	+ Add to cart

Note: 25' lengths may not work at 4K 60Hz with all setups.

Q: Why do some part numbers end in E instead of C?

A: We're shuffling some part numbers around internally, but don't worry - they're functionally still the same cable!

Technical Documents



Get your installations done right with our convenient DisplayPort digital video panel-mount cables. Installation with mounting cables instead of couplers means the fewest connections possible, maintaining perfect signal clarity and reducing noise-vulnerable gaps.

About this cable: With a panelmount DisplayPort cable, you can provide remote access to a video source or display directly on a wall plate, front panel, custom enclosure, or any cuttable or punchable mounting surface. Home theaters, editing studios, computer labs, and retail displays all benefit from the cleanliness and hot-swapability of mounted DisplayPort jacks.

About DisplayPort: DisplayPort is one of the new generations of video formats, very similar to (and in competition with) HDMI. While HDMI is targeted primarily towards home theater electronics, DisplayPort is finding more popularity with computer-centric electronics. DisplayPort is capable of carrying several times the data of a DVI cable in a smaller form factor, and also carries high-fidelity digital audio.

For information about selecting, installing, and using wall plates in your applications, see our [Guide to Face Plates](#).

Related Products



DisplayPort Dual Panel-Mount F/F Cable



DisplayPort Digital Video Cable



DisplayPort Panel-Mount Coupler



Panel Mount Mini DisplayPort Extension Cable

More Information

[DataPro's Guide to UL Cable Ratings](#)

[DataPro's DisplayPort Guide and FAQ](#)

[Wall Plate Installation](#)

[Custom Wall Plates & Panel-Mount Cables](#)


[Technical Info Home](#)






Need it FAST?
We offer **Rushed Production** to meet your deadline!

Contact our Sales Department!
800-727-8890 • sales@datapro.net

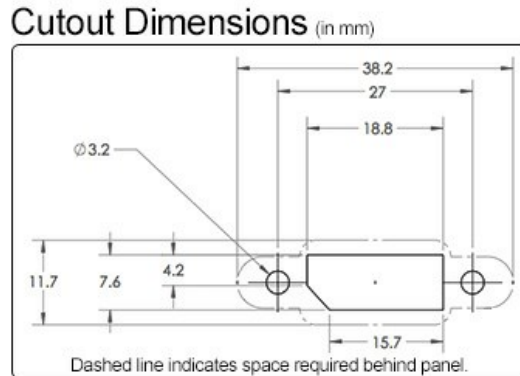

[Click here for PDF version](#)

 

Features:

- CL2 rated for in-wall use
- Includes mounting hardware
- Gold-plated contacts
- Shielded against RFI and EMI interference

Specifications:

- 1x Female DisplayPort Connector
- 1x Locking Male DisplayPort Connector
- Supports resolutions up to 4K UHD @ 60Hz
- Wire Gauge 28 AWG
- RoHS Compliant
- CL2 rated
- Embedded 4-40 nuts with mounting screws included
- Allowable panel depth: 2.5mm (full mating)
- Recommended screw installation: hand tighten, 2.0 in-lbs maximum torque

Recently Viewed Products:



[DisplayPort
Panel-Mount
Extension](#)



[FAQ](#) | [Terms & Conditions](#) | [Privacy Policy](#) | [Cookie Statement](#)

© 1986-2019 DataPro International Inc., Seattle, WA

