


Part Number : [350369802](#)

Product Description : .250mm Fuse Terminal,
0.85mm² - 2.50mm²

Series Number : 35036

Status : Obsolete

Product Category : Crimp Terminals

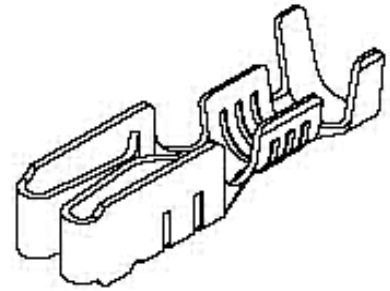

Documents and Resources


Specifications

[PK-35036-001-001.pdf](#)

[PS-35036-002-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 44
China RoHS	 per SJ/T 11365-2006
EU ELV	Compliant per 2000/53/EC
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

Part Details

General

Status	Obsolete
Category	Crimp Terminals
Series	35036
Description	.250mm Fuse Terminal, 0.85mm ² - 2.50mm ²
Application	Power, Wire-to-Component
Comments	Box Type
Product Name	N/A
UPC	800753238848

Electrical

Current - Maximum per Contact	10.0A, 18.0A
Voltage - Maximum	3V

Physical

Durability (mating cycles max)	10
Gender	Female
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.760/g
Packaging Type	Reel
Termination Interface Style	Crimp or Compression
Wire Insulation Diameter	2.20-3.10mm
Wire Size (AWG)	14, 16, 18
Wire Size mm ²	0.85-2.50