


1674311 -1 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

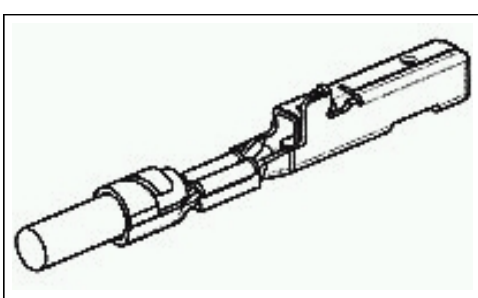

1674311 -1

Active

MULTILOCK Connectors and Contacts

Always EU RoHS/ELV Compliant ([Statement of Compliance](#))

Product Highlights:

- ? Contact
- ? Terminate To Wire
- ? Receptacle
- ? Wire Range = 0.30 - 0.60² [22 - 20] mm [AWG]
- ? Insulation Diameter = 1.40 - 1.70 mm

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [0.64III SERIES CONNECTOR RECEPTACLE CONTACT](#) (PDF, Japanese)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? [025\(0.64\)/375\(9.5\) HYBRID Connector \(1\)](#) (TIF, Japanese)
- ? [025\(0.64\)/375\(9.5\) HYBRID Connector \(2\)](#) (PDF, Japanese)
- ? [0.64III/1.0III SERIES CONNECTOR \(1\)](#) (PDF, Japanese)
- ? [0.64III/1.0III SERIES CONNECTOR \(2\)](#) (PDF, Japanese)
- ? [0.64III SERIES CONNECTOR 2ROW \(1\)](#) (PDF, Japanese)
- ? [0.64III SERIES CONNECTOR 2ROW \(2\)](#) (PDF, Japanese)
- ? [0.64III/2.3II CONNECTOR \(1\)](#) (TIF, Japanese)
- ? [0.64III/2.3II CONNECTOR \(2\)](#) (TIF, Japanese)
- ? [0.64 Series Connector 4postion](#) (PDF, Japanese)
- ? [0.64 SERIES I/O CONNECTOR\(SMD -Top Entry,Vertical... \(1\)](#) (PDF, Japanese)
- ? [0.64 SERIES I/O CONNECTOR\(SMD -Top Entry,Vertical... \(2\)](#) (PDF, Japanese)
- ? [0.64\(025\) 6POS CONNECTOR FOR RESOLVER](#) (TIF, Japanese)

Application Specifications:

- ? [CRIMPING OF 0.64III RECEPTACLE CONTACT](#) (PDF, Japanese)
- ? [CRIMPING OF 0.64III RECEPTACLE CONTACT \(JAPANESE VER...](#) (TIF, Japanese)

Instruction Sheets:

- ? [0.64III/1.0III SERIES CONNECTOR \(1\)](#) (TIF, Japanese)
- ? [0.64III/1.0III SERIES CONNECTOR \(2\)](#) (TIF, Japanese)
- ? [Extraction Tool for 0.64III Housing Lance Receptacle...](#) (PDF, Japanese)
- ? [0.64/9.5 HYBRID CONNECTOR \(1\)](#) (PDF, Japanese)
- ? [0.64/9.5 HYBRID CONNECTOR \(2\)](#) (PDF, Japanese)
- ? [0.64 Series Connector 4position](#) (PDF, Japanese)

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Product Type](#) = Contact
- ? [Tab/Receptacle](#) = Receptacle
- ? [Insulation Diameter \(mm \[in\]\)](#) = 1.40 - 1.70 [0.055 - 0.067]
- ? Proprietary Name = MULTILOCK
- ? Product Series = 0.64 III

Body Related Features:

- ? [Wire Range \(mm \[AWG\]\)](#) = 0.30 - 0.60² [22 - 20]

Contact Related Features:

- ? [Contact Material](#) = Copper Alloy
- ? [Contact Mating Area Plating Material](#) = Pre - Tin

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Conditions for Usage:

- ? [Terminate To](#) = Wire

Packaging Related Features:

- ? [Packaging Method](#) = Strip

Other:

- ? Brand = AMP