


FLEX STACK

MICRO BOARD STACKER

(1.27 mm) .050" PITCH • FW SERIES

4
Gbps

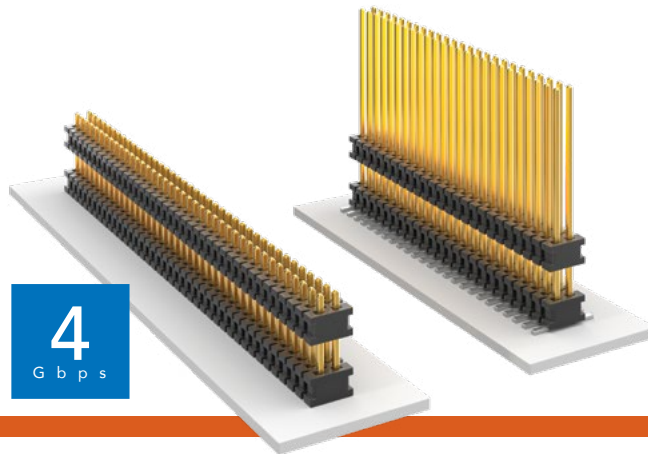

FW
Board Mates:
CLP, FLE

Cable Mates:
FFSD

SPECIFICATIONS

Insulator Material:
Black Liquid Crystal Polymer
Terminal Material:
Phosphor Bronze
Plating:
Sn or Au over 50 μ " (1.27 μ m) Ni
Operating Temp Range:
-55 $^{\circ}$ C to +125 $^{\circ}$ C

PROCESSING

Lead-Free Solderable:
Yes
SMT Lead Coplanarity:
(0.10 mm) .004" max (02-30)
(0.15 mm) .006" max (31-50)*
*(.004" stencil solution
may be available; contact
ipg@samtec.com)

MATED HEIGHT

FW LEAD STYLE	CLP LEAD STYLE	MATED HEIGHT*
FW-XX-03-X-X-233-065	-02	8.13 mm) .329"
FW-XX-03-X-X-303-065		9.91 mm) .390"

*Processing conditions will affect mated height.

ALSO AVAILABLE


Smaller stack heights
(MOQ Required)

Notes:
For added mechanical stability,
Samtec recommends
mechanical board spacers
be used in applications
with gold or selective gold
plated connectors. Contact
ipg@samtec.com for more
information.








This Series is non-standard,
non-returnable.

FW	NO. OF PINS PER ROW	LEAD STYLE	PLATING OPTION	D	STACKER HEIGHT	POST HEIGHT	OPTION
	02 thru 50	Specify LEAD STYLE from chart	-F = Gold flash on post, Matte Tin on tail -L = 10 μ " (0.25 μ m) Gold on post, Matte Tin on tail -G = 10 μ " (0.25 μ m) Gold on post, Gold flash on tail		-"XXX" = Stacker Height (in inches) Example: -250 = (6.35 mm) .250"	-"XXX" = Post Height (in inches) (1.65 mm) .065" minimum Example: -.065 = (1.65 mm) .065"	-ES = End Shroud (-.075 post height only. Mate only with CLP) (5.46 mm) .215" to (15.49 mm) .610" stacker height only 9 pins/row min. -EP = End Shroud with Guide Post (-.075 post height only. Mate only with CLP) (5.46 mm) .215" to (15.49 mm) .610" stacker height only 9 pins/row min. -A = Alignment Pin (3 positions min.) (5.46 mm) .215" to (15.75 mm) .620" stacker height only (SMT only) -P = Pick & Place Pad (5 positions min.) (SMT only) -TR = Tape & Reel (Max overall height = Post+Stacker Height+Pad+ Alignment Pin = (17.78) .700") (SMT only) -FR = Full Reel Tape & Reel (must order max. quantity per reel; contact Samtec for quantity breaks) (SMT only)





LEAD STYLE	STACKER HEIGHT	STACKER + POST
-03	(5.46) to (8.51) .215 .335	(7.11) to (10.16) .280 .400
-05	(8.64) to (15.49) .340 .610	(10.29) to (17.15) .405 .675

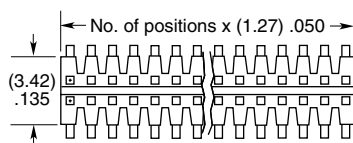

SURFACE MOUNT

    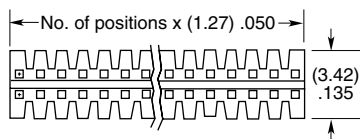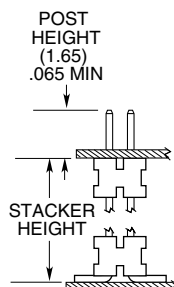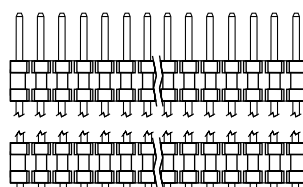

THROUGH-HOLE

  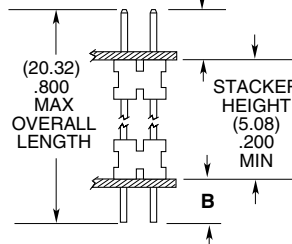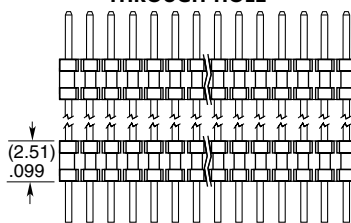

LEAD STYLE	TAIL (B)
-01	(1.14) .045
-02	(1.91) .075
-04	(2.29) .090

samtec.com?FW-SM or samtec.com?FW-TH

F-224