


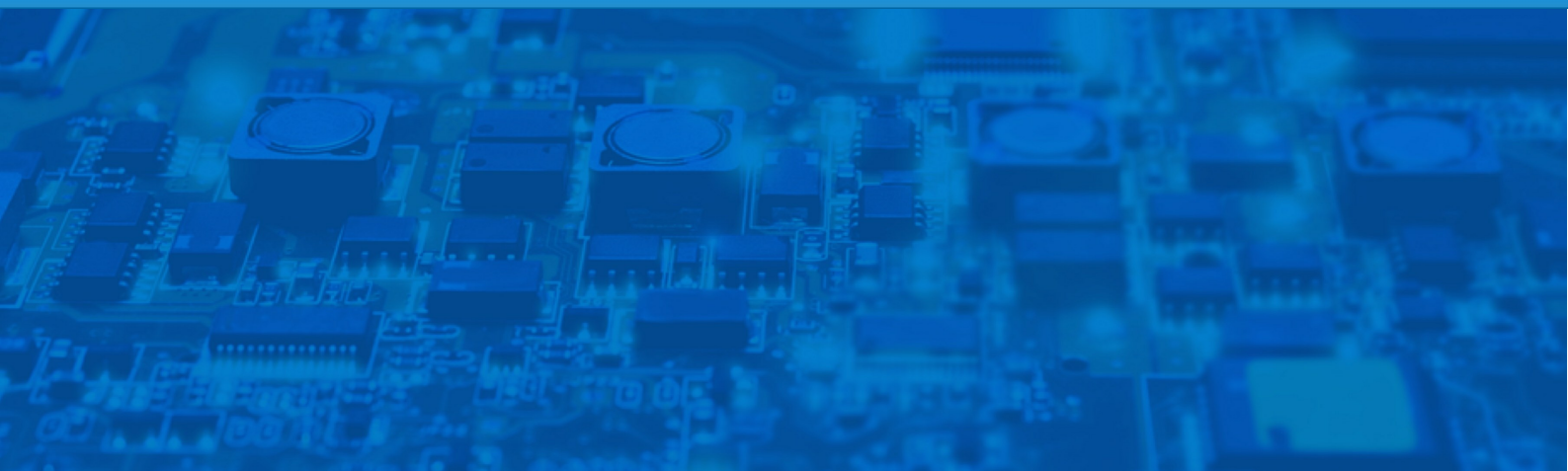

Home > 3048-B-440-B



Swage Standoffs

Model: 3048-B-440-B

Select Finish

-0 No Plate



Request Quote

[Request Custom Part](#)

RFQ

Product Details

These standoffs are made of Brass. They are Round shaped with diameter as 1/4". The thread for this part is 4-40 and length is 5/16".

SWAGE TOOLING

±.003	S	P
.075	A	1/32
.105	B	1/16
.135	C	3/32
.165	D	1/8
.230	E	3/16
.290	F	1/4

PDF Catalog

[RAF_catalog_0097.pdf](#)

O.D.	1/4"
Shape	Round
Length (L)	5/16"
Material	Brass
RoHS	Yes
Shank Length	0.105"
Board Thickness	1/16"
Shank Diameter	0.188"
Thread Clearance	0.150"
Finish	-0 No Plate



RAF ELECTRONIC
HARDWARE

TECHNICAL INFORMATION

Electronic Hardware Components
Engineering Data

COMPANY

RAF Quality Management
Industry Links