



Color:  white



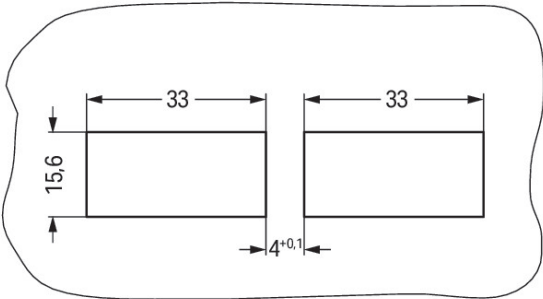


Plate thickness: 0.5 ... 2 mm  
Cutout tolerance: + 0.1 mm


Dimensions in mm

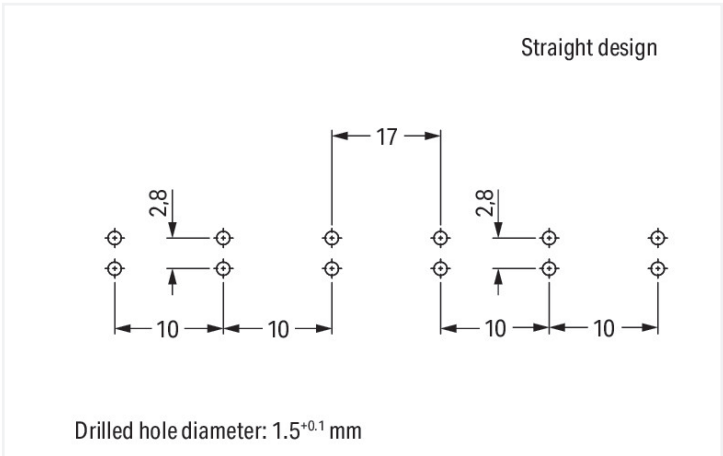

Dimensions in mm

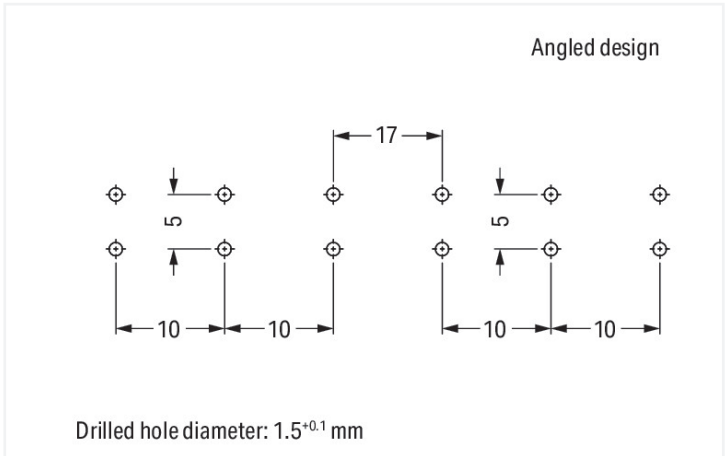

Dimensions in mm

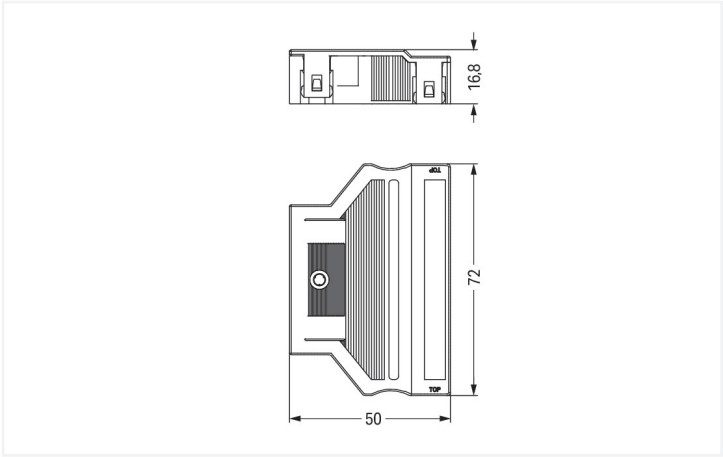

Dimensions in mm



Strain relief housing *WINSTA*® MIDI 6-pole

Thanks to the strain relief housing from the *WINSTA*® MIDI product line, straightforward electrical installation is guaranteed. An extensive range of accessories rounds out the *WINSTA*® product line from WAGO. The *WINSTA*® MIDI product line allows maximum flexibility for the installation. Through its Push-in CAGE CLAMP® spring pressure connection technology, it guarantees time-saving, error-free installation and offers customization for meeting all installation requirements. The strip length is 55 mm.

*WINSTA*® MIDI solutions for your electrical installation – protected against mismatching and maintenance-free

The *WINSTA*® Pluggable Connection System allows pluggable electrical installation. This significantly reduces the need for servicing and lowers costs. Enjoy the benefits of the pluggable version of our maintenance-free spring pressure connection technology too! Plan your installation with with protection against mismatching from WAGO.

- for automation controllers
- quick replacement of defective units during ongoing operation



Connection data

Connection 1	
Pole number	6
Connectable sheathed cable diameter	8.5 ... 13.5 mm
Strip length (outer insulation)	55 mm

Physical data

Pin spacing	10 mm / 0.394 inches
Width	72 mm / 2.835 inches
Height	16.8 mm / 0.661 inches
Depth	50 mm / 1.969 inches

Material data

Note (material data)	<a href="#">Information on material specifications can be found here</a>
Color	white
Insulation material (main housing)	Polyamide (PA66)
Flammability class per UL94	V0
Fire load	0.466 MJ
Weight	16.6 g

Environmental requirements

Processing temperature	-5 ... +40 °C
Continuous operating temperature	-35 ... +85 °C
Note on continuous operating temperature	Insulating parts for temperatures ≤ 105 °C

Commercial data

PU (SPU)	20 pcs
Packaging type	Box
Country of origin	DE
GTIN	4045454001810
Customs tariff number	85389099990

Product classification

UNSPSC	39121402
--------	----------

Environmental Product Compliance

RoHS Compliance Status	Compliant, No Exemption
------------------------	-------------------------



Approvals / Certificates

Approvals for marine applications



Approval	Standard	Certificate Name
LR Lloyds Register	IEC 61984	LR22429487TA

Downloads

Environmental Product Compliance

Compliance Search

Environmental Product Compliance 770-516/029-000	
---	--

Documentation

Bid Text

770-516/029-000	19.02.2019	xml 2.84 KB	
770-516/029-000	06.01.2015	doc 23.50 KB	

CAD/CAE-Data

CAD data

2D/3D Models 770-516/029-000	
---------------------------------	--

CAE data

WSCAD Universe 770-516/029-000	
ZUKEN Portal 770-516/029-000	

1 Compatible Products

1.1 Optional Accessories

1.1.1 Marking

1.1.1.1 Marking strip





Item No.: 210-333

Marking strips; as a DIN A4 sheet; Strip width 6 mm; Strip length 182 mm; plain; Self-adhesive; white

## Installation Notes

### Application

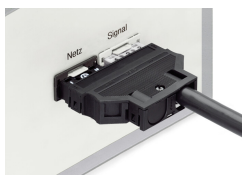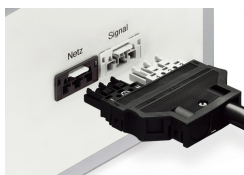

Snap-on type strain relief housings for:

- Two 3-pole sockets
- Two 3-pole plugs
- Three-pole socket and plug