

Housing - HC-STA-B24-HHFS-1STP29-EL-AL



1412760

<https://www.phoenixcontact.com/us/products/1412760>

Please be informed that the data shown in this PDF document is generated from our Online Catalog. Please find the complete data in the user documentation. Our General Terms of Use for Downloads are valid.



Sleeve housing B24, for single locking latch, material: Die-cast aluminum, salt water resistant, cable outlets: 1, lateral, 1x Pg29, height: 76 mm, cable gland: none, Standard

Your advantages

- good shielding in the event of electromagnetic interference

Housing - HC-STA-B24-HHFS-1STP29-EL-AL



1412760

<https://www.phoenixcontact.com/us/products/1412760>

Commercial Data

| | |
|--------------------------------------|---------------------|
| Item number | 1412760 |
| Packing unit | 1 pc |
| Minimum order quantity | 1 pc |
| Sales Key | B10 |
| Product Key | BF7APB |
| Catalog Page | Page 634 (C-2-2019) |
| GTIN | 4055626060262 |
| Weight per Piece (including packing) | 285.7 g |
| Weight per Piece (excluding packing) | 285.7 g |
| Customs tariff number | 85389099 |
| Country of origin | PL |

Housing - HC-STA-B24-HHFS-1STP29-EL-AL



1412760

<https://www.phoenixcontact.com/us/products/1412760>

Technical Data

 
Notes

| | |
|---------|--|
| General | for contact inserts HC-B24, BB46, D64, DD108, HV10/16, M |
|---------|--|

Product properties

| | |
|------------------------------|----------------------------|
| Type | B24 |
| Product type | Housing with locking latch |
| Application | Standard |
| No. of cable outlets | 1 |
| Type of the screw connection | 1x Pg29 |
| Housing type | Sleeve housing |
| Locking type | for single locking latch |
| Cable outlet | lateral |
| Pg screw connection | none |

Dimensions

| | |
|---------------------|--|
| Dimensional drawing |  |
| Width | 44 mm |
| Height | 76 mm |
| Length | 120 mm |

Internal dimensions

| | |
|---------------------------|-------|
| Length of internal thread | 14 mm |
|---------------------------|-------|

Material specifications

| | |
|--------------------------|---|
| Color | gray aluminum |
| Housing surface material | uncoated |
| Impact strength | IK08 |
| Housing material | Die-cast aluminum, salt water resistant |

Ambient conditions

| | |
|---------------------------------|-------------------|
| Degree of protection | IP66 |
| | IP67 |
| Degree of protection | 4 (UL 50e) |
| | 4X (UL 50e) |
| | 12 (UL 50e) |
| Impact strength | IK08 |
| Ambient temperature (operation) | -40 °C ... 125 °C |

Housing - HC-STA-B24-HHFS-1STP29-EL-AL



1412760

<https://www.phoenixcontact.com/us/products/1412760>

Mechanical properties

Mechanical data

| | |
|------------------------------|---------|
| Type of the screw connection | 1x Pg29 |
| Locking type | Pin |

Housing - HC-STA-B24-HHFS-1STP29-EL-AL


1412760

<https://www.phoenixcontact.com/us/products/1412760>



Drawings

Dimensional drawing

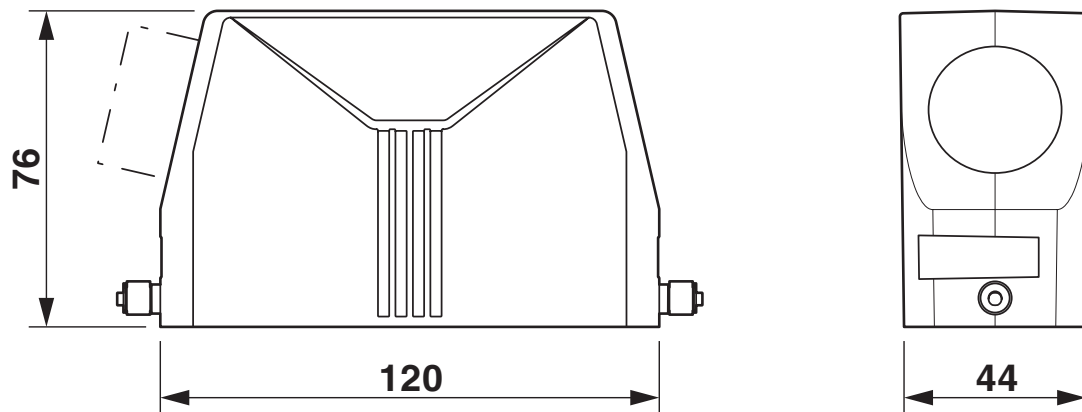

Dimensional drawing


Housing - HC-STA-B24-HHFS-1STP29-EL-AL





1412760

<https://www.phoenixcontact.com/us/products/1412760>

Approvals

**DNV**
Approval ID: TAE000037S

**cUL Recognized**
Approval ID: E255026

**UL Recognized**
Approval ID: E255026

**EAC**
Approval ID: RU C-DE.AI30.B.01102

**EAC**
Approval ID: RU C-DE.BL08.B.00511

cULus Recognized

Housing - HC-STA-B24-HHFS-1STP29-EL-AL



1412760

<https://www.phoenixcontact.com/us/products/1412760>

Classifications

ECLASS

| | |
|---------------|----------|
| ECLASS-9.0 | 27440202 |
| ECLASS-10.0.1 | 27440202 |
| ECLASS-11.0 | 27440202 |

ETIM

| | |
|----------|----------|
| ETIM 8.0 | EC000437 |
|----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

Environmental Product Compliance

| | |
|------------|---|
| China RoHS | Environmentally friendly use period: unlimited = EFUP-e |
| | No hazardous substances above threshold values |

Housing - HC-STA-B24-HHFS-1STP29-EL-AL



1412760

<https://www.phoenixcontact.com/us/products/1412760>

Accessories

Cable gland

Cable gland - G-INS-PG29-M68N-NNES-S - 1411176

<https://www.phoenixcontact.com/us/products/1411176>



Cable gland, cable gland material: Nickel-plated brass, external cable diameter 18 mm ... 25 mm, shielding: no, connecting thread: Pg29, color: silver, with O-ring

Screw connection

Screw connection - WP-G HF IP66 PG29 BK - 3240893

<https://www.phoenixcontact.com/us/products/3240893>



Cable gland, Pg thread, IP66 protection, straight

Housing - HC-STA-B24-HHFS-1STP29-EL-AL



1412760

<https://www.phoenixcontact.com/us/products/1412760>

Cable gland

Cable gland - G-INSEC-PG29-M68N-NNES-S - 1411201

<https://www.phoenixcontact.com/us/products/1411201>



Cable gland, cable gland material: Nickel-plated brass, external cable diameter 18 mm ... 25 mm, shielding: yes, connecting thread: Pg29, color: silver, with O-ring

Screw connection

Screw connection - WP-G HF IP69K PG29 BK - 3240879

<https://www.phoenixcontact.com/us/products/3240879>



Cable gland, Pg thread, IP68/69k protection, straight

Housing - HC-STA-B24-HHFS-1STP29-EL-AL



1412760

<https://www.phoenixcontact.com/us/products/1412760>

Plastic label

Plastic label - US-EMLP (20X9) CUS - 0830085

<https://www.phoenixcontact.com/us/products/0830085>

Plastic label, can be ordered: by card, white, labeled according to customer specifications, mounting type: adhesive, lettering field size: 20 x 9 mm, Number of individual labels: 75



Screw connection

Screw connection - WP-GA HF IP66 PG29 BK - 3240921

<https://www.phoenixcontact.com/us/products/3240921>

Cable gland, Pg thread, IP66 protection, angled



Housing - HC-STA-B24-HHFS-1STP29-EL-AL



1412760

<https://www.phoenixcontact.com/us/products/1412760>

Protective cover

Protective cover - HC-B24-HCLWS-PLR-BK - 1414637

<https://www.phoenixcontact.com/us/products/1414637>



Protective cover B24, with single locking latch, protective cover material: PA, height: 21.6 mm, seal: yes, diameter of retaining cord eyelet: 30 mm

Screw connection

Screw connection - WP-GA HF IP69K PG29 BK - 3240907

<https://www.phoenixcontact.com/us/products/3240907>



Cable gland, Pg thread, IP68/69k protection, angled

Housing - HC-STA-B24-HHFS-1STP29-EL-AL



1412760

<https://www.phoenixcontact.com/us/products/1412760>

Screw connection

Screw connection - WP-GR HF IP66 PG29 BK - 3240949

<https://www.phoenixcontact.com/us/products/3240949>



Cable gland, Pg thread, IP66 protection, with strain relief

Screw connection

Screw connection - WP-GR HF IP69K PG29 BK - 3240935

<https://www.phoenixcontact.com/us/products/3240935>



Cable gland, Pg thread, IP68/69k protection, with strain relief

Housing - HC-STA-B24-HHFS-1STP29-EL-AL



1412760

<https://www.phoenixcontact.com/us/products/1412760>

Screw connection

Screw connection - WP-G PP HF PG29 - 3240993

<https://www.phoenixcontact.com/us/products/3240993>

Cable gland made from PP with Pg thread, IP65 protection



Screw connection

Screw connection - WP-GT PP HF PG29 - 3241007

<https://www.phoenixcontact.com/us/products/3241007>

Cable gland made from PP with Pg thread, rotatable, IP54 protection



Housing - HC-STA-B24-HHFS-1STP29-EL-AL



1412760

<https://www.phoenixcontact.com/us/products/1412760>

Screw connection

Screw connection - WP-G BRASS IP40 PG29 - 3241042

<https://www.phoenixcontact.com/us/products/3241042>



Cable gland made from brass with Pg thread, IP40 protection

Screw connection

Screw connection - WP-GT BRASS PG29 - 3241028

<https://www.phoenixcontact.com/us/products/3241028>



Cable gland made from brass with Pg thread, rotatable, IP40 protection

Housing - HC-STA-B24-HHFS-1STP29-EL-AL

1412760

<https://www.phoenixcontact.com/us/products/1412760>



Screw connection

Screw connection - WP-G BRASS IP65 PG29 - 3241056

<https://www.phoenixcontact.com/us/products/3241056>



Cable gland made from brass with Pg thread, IP65 protection

Phoenix Contact 2022 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com