

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0444763112

Status:

Active

Overview:

Mini-Fit® Plus HCS

Description:

Mini-Fit® HCS Crimp Terminal, 16 AWG, Bag, Copper (Cu) Alloy, Tin (Sn)


Documents:

Drawing (PDF)

Product Specification PS-44476-001 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Terminals
Series	44476
Application	Power
Comments	High Current
Crimp Quality Equipment	Yes
Overview	Mini-Fit® Plus HCS
Product Name	Mini-Fit®
UPC	800754367394
Physical	
Gender	Female
Material - Metal	High Performance Alloy (HPA)
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.100/g
Packaging Type	Bag
Plating min - Mating	2.540µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.80-3.10mm
Wire Size AWG	16
Wire Size mm²	N/A
Electrical	
Current - Maximum per Contact	11.0A
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Product Specification	PS-44476-001, RPS-44476-001

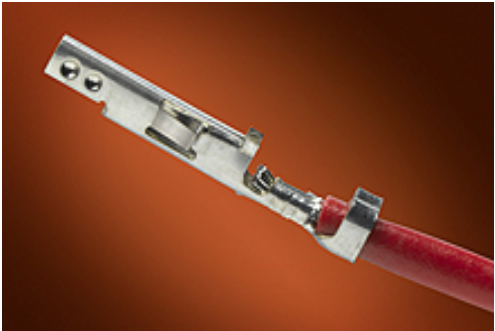

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Contains SVHC(2014

December 17): No

Halogen-Free

Status

Low-Halogen

Need more information on product

environmental compliance?

Email productcompliance@molex.com

Please visit the Contact Us section for any

non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

Search Parts in this Series

44476 Series

Application Tooling | FAQ

Tooling specifications and manuals are

found by selecting the products below.

Crimp Height Specifications are then

contained in the Application Tooling

Specification document.

Global

Description

Product #

Hand Crimp Tool for

Male and Female

Crimp Terminals,

16-24 AWG Wire

Extraction Tool

Manual Extraction

Tool

0638190900

0011030044

0638131200

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION