



## Data Sheet | Item Number: 734-227

Strain relief plate; for female and male connectors; 6 mm wide; 1 part; Pin spacing 3.81 mm; orange

<https://www.wago.com/734-227>

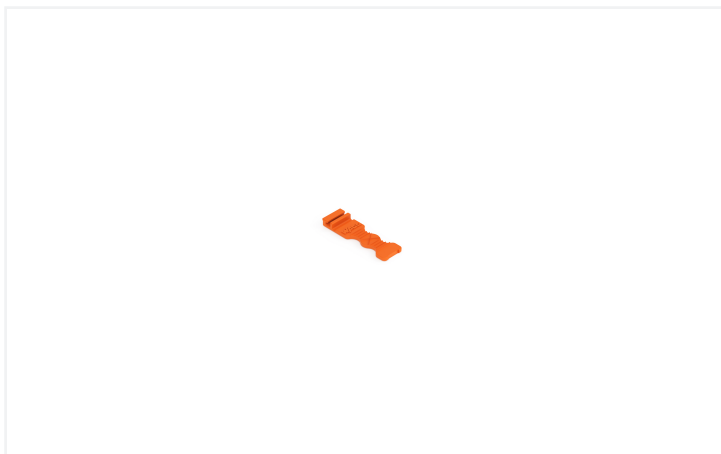

Color: ■ orange

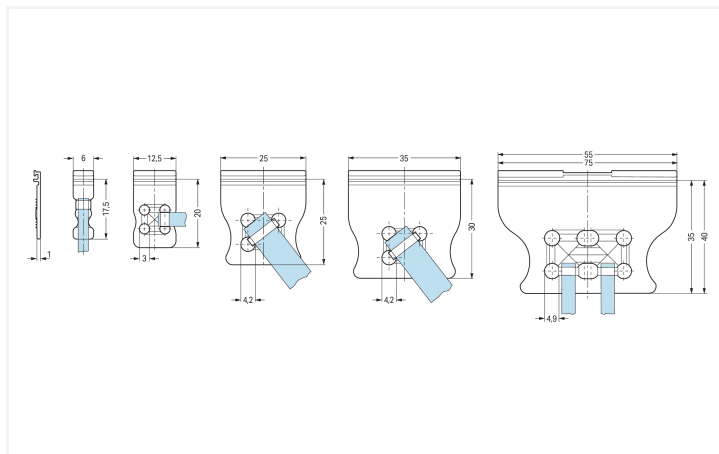

Dimensions in mm

The arrangement of the attachments for cable ties allows single conductors or multi-core cables to be secured in different ways. The width of the cable ties must correspond to the hole dimensions of the strain relief plates shown above.

### Physical data

Width	6 mm / 0.236 inches
Height	1.87 mm / 0.074 inches
Depth	19.5 mm / 0.768 inches

### Mechanical data

Mounting type	Insert
Suitable	for standard male and female connectors (3.81 mm; 5.08 mm; 7.62 mm pin spacing)

### Material data

Note (material data)	<a href="#">Information on material specifications can be found here</a>
Color	orange
Material group	I
Insulation material (main housing)	Polyamide (PA66)
Flammability class per UL94	V0
Fire load	0.004 MJ
Weight	0.1 g

**Commercial data**

Product Group	3 (Multi Conn. System)
PU (SPU)	100 (25) pcs
Packaging type	Box
Country of origin	DE
GTIN	4017332404907
Customs tariff number	85389099990

**Product Classification**

UNSPSC	39121421
eCl@ss 10.0	27-44-04-92
eCl@ss 9.0	27-44-04-92
ETIM 9.0	EC002848
ETIM 10.0	EC002848
ECCN	NO US CLASSIFICATION

**Environmental Product Compliance**

RoHS Compliance Status	Compliant, No Exemption
------------------------	-------------------------

**Approvals / Certificates**

**Approvals for marine applications**



Approval	Standard	Certificate Name
LR Lloyds Register	IEC 61984	96/20035 (E5)

**Downloads**

**Environmental Product Compliance**

Compliance Search	
Environmental Product Compliance 734-227	↓

**Documentation**

**Additional Information**

Technical Section	03.04.2019	pdf 2027.26 KB	↓
-------------------	------------	-------------------	---

## CAD/CAE-Data

### CAD data

2D/3D Models 734-227




### CAE data

ZUKEN Portal 734-227



## Installation Notes

### Installation

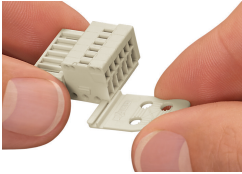


Strain relief plates for factory or in-the-field assembly

## Application



Strain relief plate, for factory assembly  
1-conductor female connector, 2.5 mm pin spacing, light gray,  
12-pole, with strain relief plate  
733-112/034-000

## Application

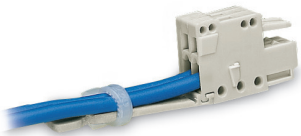

Strain relief plate, for factory assembly  
1-conductor female connector, 2.5 mm pin spacing, light gray,  
2-pole, with strain relief plate  
(733-102/032-000)