

Housing - HC-ADV-B10-HLWH-1STM25-EMC-AL



1413391

<https://www.phoenixcontact.com/us/products/1413391>

Please be informed that the data shown in this PDF document is generated from our Online Catalog. Please find the complete data in the user documentation. Our General Terms of Use for Downloads are valid.



HEAVYCON ADVANCE sleeve housing, B10, with stainless steel screw locking (Allen screw), salt-water-resistant aluminum, height 74 mm, with 1x M25 thread, lateral cable outlet, without surface; conductive seal (EMC properties)

Commercial Data

Item number	1413391
Packing unit	1 pc
Minimum order quantity	1 pc
Sales Key	B10
Product Key	BF7APH
Catalog Page	Page 603 (C-2-2019)
GTIN	4055626030265
Weight per Piece (including packing)	230 g
Weight per Piece (excluding packing)	229.32 g
Customs tariff number	85389099
Country of origin	CN

Technical Data


Notes

General	For contact inserts HC-B10, BB18, DD42, M, K8/24
---------	--

Product properties

Type	B10
Product type	Housing with screw locking
Application	Offshore/EMC
No. of cable outlets	1
Type of the screw connection	1x M25
Fixing screws	M6 (screw head: 5 mm Allen screw)
Housing type	Sleeve housing
Locking type	with screw locking
Cable outlet	lateral
Pg screw connection	none

Dimensions

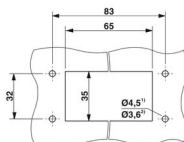Dimensional drawing	
Width	57 mm
Height	74 mm
Length	105 mm

Installation dimensions

Width of the assembly cutout	35 mm
Length of the assembly cutout	65 mm

Material specifications

Color	gray aluminum
Sealing material	NBR, conductive
Housing surface material	uncoated
Locking latch material	Stainless steel
Impact strength	IK09
Housing material	Die-cast aluminum, salt water resistant

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP66
	IP68 (0.2 bar/24 h)

Housing - HC-ADV-B10-HLWH-1STM25-EMC-AL



1413391

<https://www.phoenixcontact.com/us/products/1413391>

	IP69 (ISO 20653:2013-02)
Degree of protection	4 (UL 50e)
	4X (UL 50e)
	12 (UL 50e)
Impact strength	IK09
Ambient temperature (operation)	-40 °C ... 125 °C

Mechanical properties

Mechanical data


Type of the screw connection	1x M25
Locking type	Screw

Mounting

Fixing screws	M6 (screw head: 5 mm Allen screw)
---------------	-----------------------------------

Drawings

Dimensional drawing

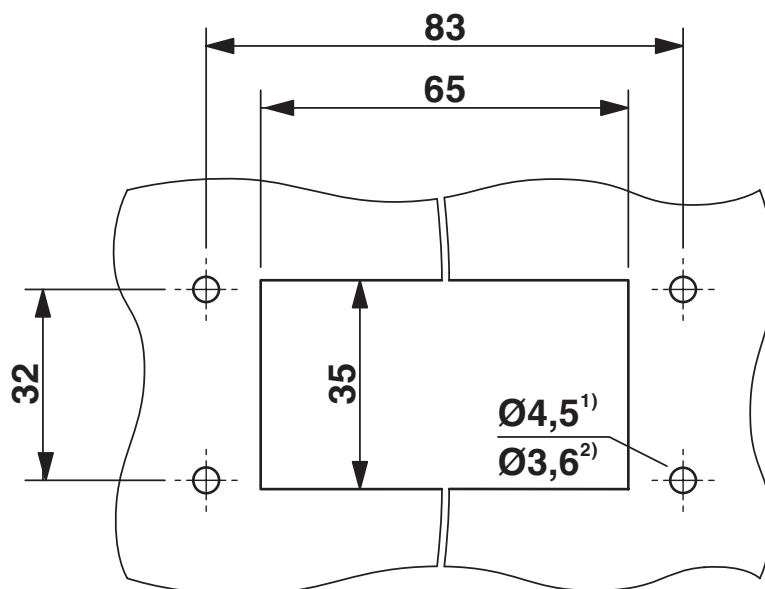


Mounting cutout

1) when M4 screws are used

2) when self-tapping Torx® screws are used (Torx® 20, M4)

Dimensional drawing

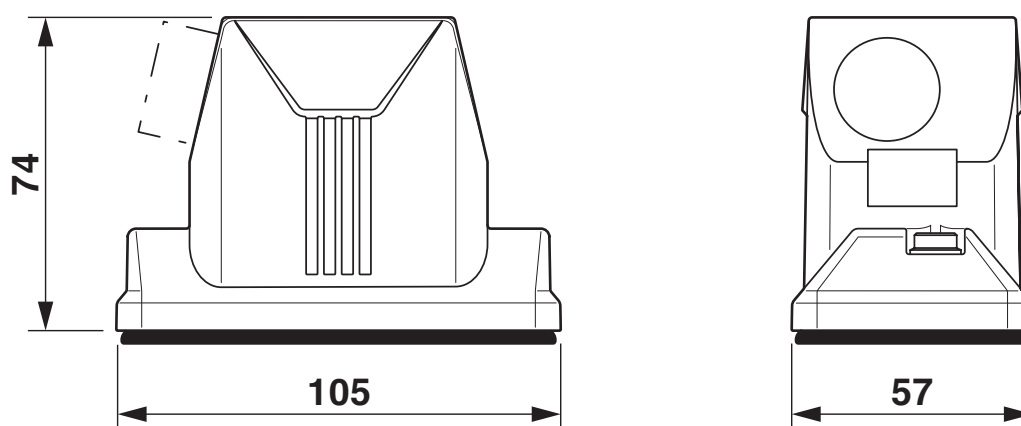

Dimensional drawing


Housing - HC-ADV-B10-HLWH-1STM25-EMC-AL




1413391

<https://www.phoenixcontact.com/us/products/1413391>


Approvals



DNV
Approval ID: TAE000037S




cUL Recognized
Approval ID: E255026



UL Recognized
Approval ID: E255026



EAC
Approval ID: RU C-DE.AI30.B.01102



EAC
Approval ID: RU C-DE.BL08.B.00511

cULus Recognized

Housing - HC-ADV-B10-HLWH-1STM25-EMC-AL



1413391

<https://www.phoenixcontact.com/us/products/1413391>

Classifications

ECLASS

ECLASS-9.0	27440202
ECLASS-10.0.1	27440202
ECLASS-11.0	27440202

ETIM

ETIM 8.0	EC000437
----------	----------

UNSPSC

UNSPSC 21.0	31261500
-------------	----------



1413391

<https://www.phoenixcontact.com/us/products/1413391>

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Housing - HC-ADV-B10-HLWH-1STM25-EMC-AL



1413391

<https://www.phoenixcontact.com/us/products/1413391>

Accessories

Panel-mount flange

Panel-mount flange - HC-B-AF - 1686533

<https://www.phoenixcontact.com/us/products/1686533>




Panel-mount flange for HEAVYCON ADVANCE housing

Panel-mount flange

Panel-mount flange - HC-B-AF-SET - 1604638

<https://www.phoenixcontact.com/us/products/1604638>

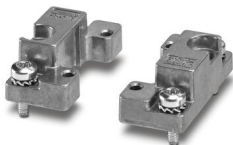

Panel-mount flange for HEAVYCON ADVANCE housing, set consisting of:
2 panel-mount flanges with 4 self-tapping screws (M4, Torx[®]) and 4 fan-type washers

Housing - HC-ADV-B10-HLWH-1STM25-EMC-AL



1413391

<https://www.phoenixcontact.com/us/products/1413391>

Protective cover

Protective cover - HC-B 10-TMS-SD-IP50 - 1690749

<https://www.phoenixcontact.com/us/products/1690749>



Protective cover B10, Clip locking, protective cover material: PA, height: 31.2 mm, seal: no, with lanyard

Protective cover

Protective cover - HC-B 10-TMS-SD-IP66 - 1411504

<https://www.phoenixcontact.com/us/products/1411504>



HEAVYCON ADVANCE, IP66, B10 protective cover for panel mounting side, with screw locking, with retaining cord, diameter of retaining cord eyelet: 3 mm

Housing - HC-ADV-B10-HLWH-1STM25-EMC-AL



1413391

<https://www.phoenixcontact.com/us/products/1413391>

Screw insert

Screw insert - SF-BIT-HEXB 5-89 - 1208911

<https://www.phoenixcontact.com/us/products/1208911>



Screw bit, hexagonal with ball head, E6.3-1/4" drive, size: Hex 5 x 89 mm, hardened, suitable for holder according to DIN 3126-F 6.3/ISO 1173

Screwdriver

Screwdriver - SF-M BH - 1212070

<https://www.phoenixcontact.com/us/products/1212070>



Bit screwdriver, with 1/4" quick-action chuck, handle length 119 mm, 2-component handle, with non-slip grip, suitable for bits according to DIN 3126-C 6.3 and E 6.3/ISO 1173, magnetic

Housing - HC-ADV-B10-HLWH-1STM25-EMC-AL



1413391

<https://www.phoenixcontact.com/us/products/1413391>

Cable gland

Cable gland - G-INS-M25-M68N-NNES-S - 1411165

<https://www.phoenixcontact.com/us/products/1411165>



Cable gland, material for screw connection: Nickel-plated brass, external cable diameter 11 mm ... 17 mm, shielding: no, connecting thread: M25 x 1.5, color: silver, with O-ring

Cable gland

Cable gland - HC-M-KV-M25(14-21) - 1646007

<https://www.phoenixcontact.com/us/products/1646007>



Metal screw connection up to 5 bar, thread length: 7 mm, cable diameter: 14 - 21 mm, WAF 34, screw connection: M25

Housing - HC-ADV-B10-HLWH-1STM25-EMC-AL



1413391

<https://www.phoenixcontact.com/us/products/1413391>

Cable gland

Cable gland - HC-EMV-KV-M25(9-16,5) - 1690516

<https://www.phoenixcontact.com/us/products/1690516>



EMC screw connection up to 5 bar, thread length: 7.5 mm, cable diameter: 9.0 - 16.5 mm, WAF 29, screw connection: M25

Cable gland

Cable gland - HC-M-KV-M25(1ASI) - 1584020

<https://www.phoenixcontact.com/us/products/1584020>



Metal screw connection for an AS-Interface flat-ribbon conductor, thread type M25

Housing - HC-ADV-B10-HLWH-1STM25-EMC-AL



1413391

<https://www.phoenixcontact.com/us/products/1413391>

Cable gland

Cable gland - HC-M-KV-M25(1X10/1X11) - 1580228

<https://www.phoenixcontact.com/us/products/1580228>



Special cable screw connection M25, brass nickel-plated, grommet with 10 mm and 11 mm holes

Plastic label

Plastic label - US-EMLP (20X9) CUS - 0830085

<https://www.phoenixcontact.com/us/products/0830085>



Plastic label, can be ordered: by card, white, labeled according to customer specifications, mounting type: adhesive, lettering field size: 20 x 9 mm, Number of individual labels: 75

Housing - HC-ADV-B10-HLWH-1STM25-EMC-AL



1413391

<https://www.phoenixcontact.com/us/products/1413391>

Screw connection

Screw connection - WP-G HF IP66 M25 BK - 3240899

<https://www.phoenixcontact.com/us/products/3240899>



Cable gland, metric thread, IP66 protection, straight

Screw connection

Screw connection - WP-G HF IP69K M25 BK - 3240885

<https://www.phoenixcontact.com/us/products/3240885>



Cable gland, metric thread, IP68/69k protection, straight

Housing - HC-ADV-B10-HLWH-1STM25-EMC-AL



1413391

<https://www.phoenixcontact.com/us/products/1413391>

Screw connection

Screw connection - WP-GA HF IP66 M25 BK - 3240927

<https://www.phoenixcontact.com/us/products/3240927>

Cable gland, metric thread, IP66 protection, angled



Screw connection

Screw connection - WP-GA HF IP69K M25 BK - 3240913

<https://www.phoenixcontact.com/us/products/3240913>

Cable gland, metric thread, IP68/69k protection, angled



Housing - HC-ADV-B10-HLWH-1STM25-EMC-AL



1413391

<https://www.phoenixcontact.com/us/products/1413391>

Screw connection

Screw connection - WP-GR HF IP66 M25 BK - 3240955

<https://www.phoenixcontact.com/us/products/3240955>



Cable gland, metric thread, IP66 protection, with strain relief

Screw connection

Screw connection - WP-GR HF IP69K M25 BK - 3240941

<https://www.phoenixcontact.com/us/products/3240941>



Cable gland, metric thread, IP68/69k protection, with strain relief

Housing - HC-ADV-B10-HLWH-1STM25-EMC-AL



1413391

<https://www.phoenixcontact.com/us/products/1413391>

Screw connection

Screw connection - WP-G PP HF M25 - 3240999

<https://www.phoenixcontact.com/us/products/3240999>

Cable gland made from PP with metric thread, IP65 protection



Screw connection

Screw connection - WP-GT PP HF M25 - 3241013

<https://www.phoenixcontact.com/us/products/3241013>

Cable gland made from PP with metric thread, rotatable, IP54 protection



Housing - HC-ADV-B10-HLWH-1STM25-EMC-AL



1413391

<https://www.phoenixcontact.com/us/products/1413391>

Screw connection

Screw connection - WP-G BRASS IP40 M25 - 3241048

<https://www.phoenixcontact.com/us/products/3241048>



Cable gland made from brass with metric thread, IP40 protection

Screw connection

Screw connection - WP-GT BRASS M25 - 3241034

<https://www.phoenixcontact.com/us/products/3241034>



Cable gland made from brass with metric thread, rotatable, IP40 protection

Housing - HC-ADV-B10-HLWH-1STM25-EMC-AL



1413391

<https://www.phoenixcontact.com/us/products/1413391>

Screw connection

Screw connection - WP-G BRASS IP65 M25 - 3241062

<https://www.phoenixcontact.com/us/products/3241062>



Cable gland made from brass with metric thread, IP65 protection

Phoenix Contact 2023 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com