

**Isolierkörpermaterial**  
PBT, UL94V-0

**Kontaktmaterial**  
Messing

**Kontaktfläche**  
Ni, Au oder Sn

**Kontaktwiderstand**  
20mΩ max

**Isolationswiderstand**  
1000MΩ min

**Strombelastbarkeit**  
1A

**Betriebstemperatur**  
-40°C - +105°C

**Betriebsspannung**  
125V AC

**Prüfspannung**  
500V AC

**Verpackung**  
Kunststoffbeutelverpackung

**Insulator material**  
PBT, UL94V-0

**Contact material**  
Brass

**Plating**  
Ni, Au or Sn

**Contact resistance**  
20mΩ max

**Insulation resistance**  
1000MΩ min



**Current rating**  
1A

**Operating temperature**  
-40°C - +105°C

**Operating voltage**  
125V AC

**Test voltage**  
500V AC

**Packing**  
Polybag packing

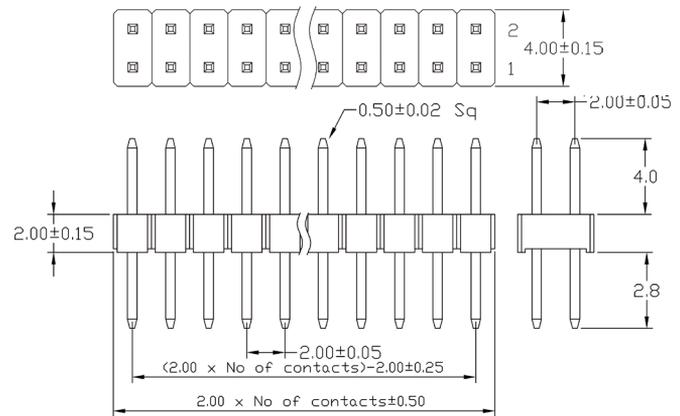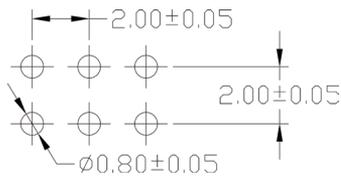

Bestellcode / Ordercode

**Kontaktfläche**

G - Gold Flash  
Z - Zinn

**Polzahl**

04 - 80

**Stiftlänge**

D - A = 4mm, B = 2,8mm

**Plating**

G - Gold flash  
Z - Tin

**No of contacts**

04 - 80

**Pin length**

D - A = 4mm, B = 2.8mm

**A - SL200 - D G - x xx D**

Bitte „x“ durch die geeignete Option ersetzen  
Please replace „x“ with appropriate option