




RF CONNECTORS

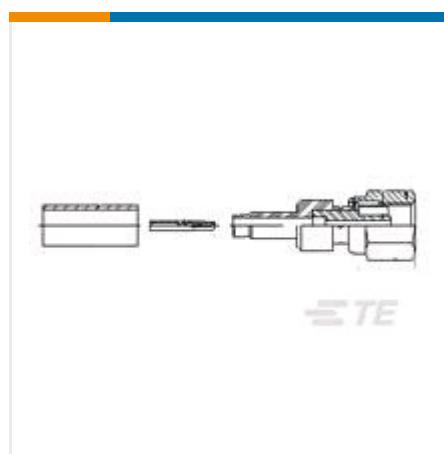

✓ Active

TE CONNECTIVITY (TE)

SMC Str Plg Hex 50Ohm Gold Pltd RG174A/U

Subminiature Coax | SMC

1-1337608-0

TE Internal Number: 1-1337608-0

EU RoHS Compliant with Exemptions

EU ELV Compliant with Exemptions

Connector Interface SMC

Connector Style Plug

Mated Outer Diameter (Approximate) 4.75 mm [.187 in]

Impedance (Ω) 50

Cable Type KX 22A, KX 3B

 **PRODUCT DRAWING**
English

DOCUMENTATION

Product Drawings

SMC STRAIGHT PLUG CRIMP 50 OHM RG174A/U, 188A/U, 316/U, URM95, KX3B, KX22A

PDF

English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

Connector Interface SMC

Connector Style Plug

Connector & Contact Terminates To Wire & Cable

Electrical Characteristics

Impedance (Ω) 50

Body Features

Cable Connector Orientation Straight

Body Material Brass

Body Plating Material Gold

Body Shape Circular

Contact Features

Crimp Type Hex

Center Contact Plating Material Gold

Center Contact Material Beryllium Copper

Termination Features

Termination Method to Wire & Cable Solder/Crimp

Mechanical Attachment

Connector Mounting Type Panel

Dimensions

Mated Outer Diameter (Approximate) 4.75 mm [.187 in]

Usage Conditions

Cable Type KX 22A, KX 3B

Packaging Features

Packaging Quantity 100

Other

Dielectric Material PTFE

Coupling Nut Material Brass

Grade Professional

PRODUCT COMPLIANCE



Statement of Compliance

Statement of Compliance

PDF
