


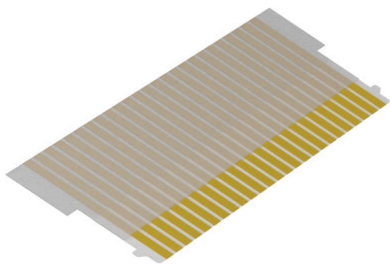

Part Number : [150190947](#)
Product Description : 1.00mm Pitch Premo-Flex FFC
Jumper, Same Side Contacts (Type A), 76.00mm Cable
Length, Gold (Au) Plating, 25 Circuits
Series Number : 15019
Status : Active
Product Category : Flat-Flexible Cable (FFC)



Documents & Resources

Drawings

- [150190947 sd.pdf](#)
- [STEP AP242](#)
- [SOLIDWORKS](#)
- [Creo](#)

Specifications

- [150190001-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C

- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Flat-Flexible Cable (FFC)
Series	15019
Description	1.00mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 76.00mm Cable Length, Gold (Au) Plating, 25 Circuits
Product Name	Premo-Flex FFC Jumper
UPC	196823477171

Electrical

Current - Maximum per Contact	1.25A
Voltage - Maximum	60V AC

Physical

Cable Length	76.00mm
Circuits (Loaded)	25
Contact Layout Type	A (same side)
Design Feature	Superior Retention
Material - Outer Jacket	Polyester
Material - Plating Mating	Gold
Packaging Type	Bag
Pitch - Mating Interface	1.00mm
Temperature Range - Operating	-40° to +105°C
Termination Style	FFC Connector

Wire/Cable Type	Flat Flex Cable
Wire Size (AWG)	N/A

Mates With / Use With

Mates with Part(s)

Description	Part Number
Easy-On FFC/FPC Connector, 1.00mm Pitch, FD19 Series, Right- Angle, Bottom Contact, 1.90mm Height, 25 Circuits, Gold over Nickel Plating	<u>2005280250</u>

This document was generated on Sep 11, 2025