


Product Status	Production
Applications	Commercial Grade
Feature	Power Power line
Series	MPZ
Brand	TDK
Environmental Compliance	 RoHS  REACH  Halogen Free  Lead Free

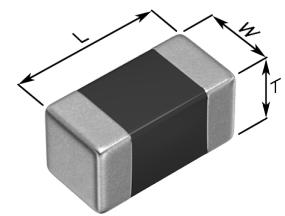

Size

Length(L)	1.60mm ± 0.15 mm
Width(W)	0.80mm ± 0.15 mm
Thickness(T)	0.80mm ± 0.15 mm
Recommended Land Pattern (A)	0.60mm Nom.
Recommended Land Pattern (B)	0.80mm Nom.
Recommended Land Pattern (C)	0.80mm Nom.

Electrical Characteristics

Impedance at 100MHz	150 Ω $\pm 25\%$
Rated Current	1.8A
DC Resistance (Max.)	50m Ω

Other


Operating Temp. Range (Including Self-Temp. Rise)	-55 to 125°C
Soldering Method	Reflow Iron Soldering
AEC-Q200	NO
Packing	Punched (Paper)Taping [180mm Reel, Tape width 8mm]
Package Quantity	4000pcs
Weight	0.004g
FIT (Failure In Time)	 This will be displayed when you login to myTDK

! Images are for reference only and show exemplary products.

! This PDF document was created based on the data listed on the TDK Corporation website.


! All specifications are subject to change without notice.

Characteristic Graphs (This is reference data, and does not guarantee the products characteristics.)

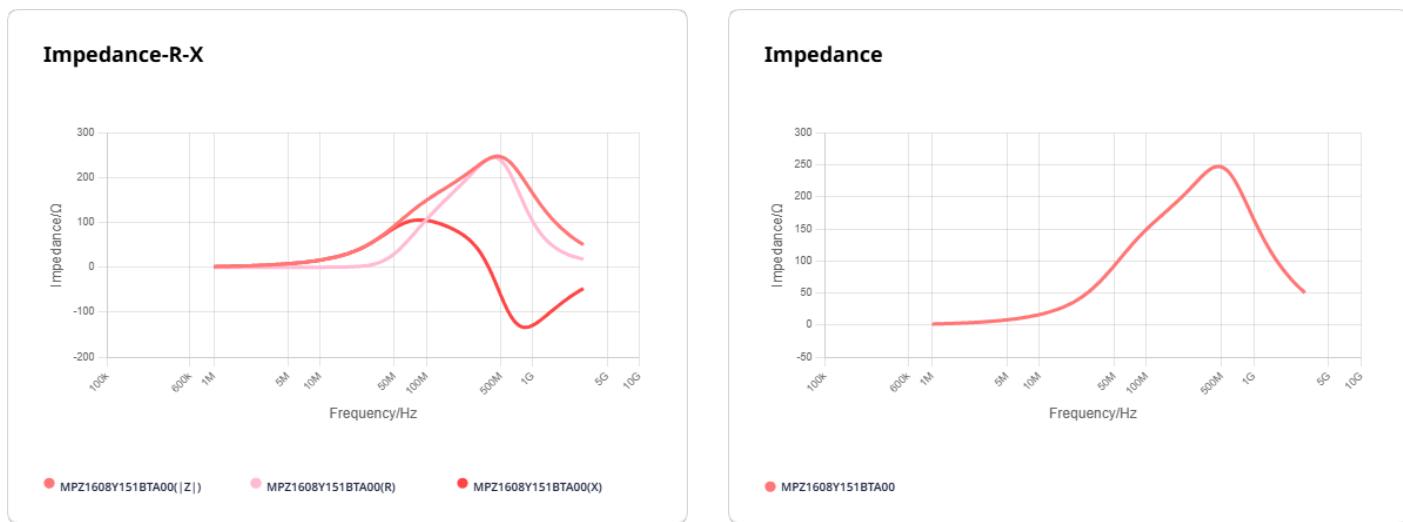

! Images are for reference only and show exemplary products.
! This PDF document was created based on the data listed on the TDK Corporation website.
! All specifications are subject to change without notice.

Associated Images

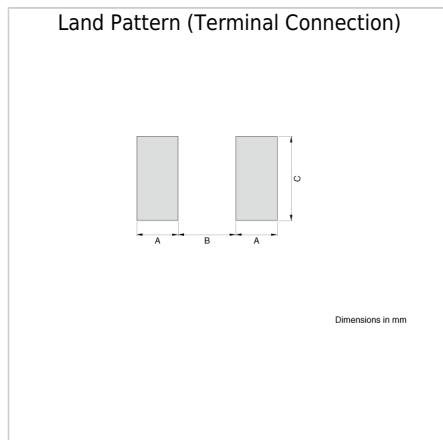

! Images are for reference only and show exemplary products.
! This PDF document was created based on the data listed on the TDK Corporation website.
! All specifications are subject to change without notice.