




+ WIRE AND CABLE

HOOK UP WIRE

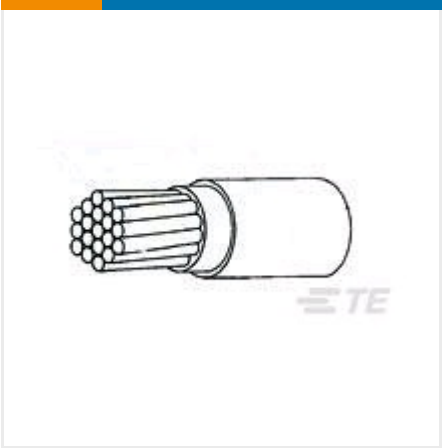

✓ Active

TE CONNECTIVITY (TE)
44A0311-24-0

Raychem | SP

44A0311-24-0
TE Internal Number: 2825013001
Alias ID: 5-1192117-5

EU RoHS Compliant
EU ELV Compliant

Cable Type Spec 44
Voltage Rating (V) 2500
Insulation Material Radiation-Crosslinked, Extruded Polyalkene
Conductor Material Tin-Plated Copper
Wire Size (AWG) 24

DOCUMENTATION

Catalog Pages/Data Sheets
1654025_Sec9_SPEC44
PDF
English

FEATURES

Please review product documents or [contact us](#) for the latest agency approval information.

Product Type Features
Cable Type Spec 44
Product Classification Cable - High Performance - Spec 44, 55 & RCW
Product Type Cable, Wire
Cable Style Primary

Configuration Features

Number of Strands 19

Number of Conductors 1

Electrical Characteristics

Voltage Rating (V) 2500

Body Features

Insulation Material Radiation-Crosslinked, Extruded Polyalkene

Conductor Material Tin-Plated Copper

Wire Color Black

Dimensions

Strand Size (AWG) 36

Wire Size (AWG) 24

Wire Size (mm²) .205

Conductor Diameter .61 mm [.024 in]

Wire Diameter 1.45 mm [.057 in]

Overall Outside Diameter 1.45 mm [.057 in]

Usage Conditions

Operating Temperature Range (°C) -65 – 150

Other

Wire Source United Kingdom, United States

PRODUCT COMPLIANCE



Statement of Compliance

Statement of Compliance
PDF