

HARTING IE Cat.7A 4x2xAWG26/7 PUR, 500m

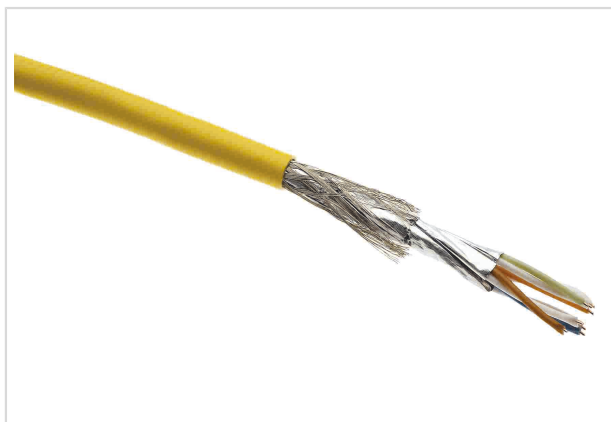


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 600 0721
Specification	HARTING IE Cat.7A 4x2xAWG26/7 PUR, 500m
HARTING eCatalogue	https://b2b.harting.com/09456000721

Identification

Category	System cabling
Element	Bulk cables
Specification	Not assembled
Type of cable	Copper cable (round)

Version

Cable length	500 m
Number of cores	8
Core structure	4x 2x AWG 26/7

Technical characteristics

Transmission characteristics	Cat. 7 Class II up to 2000 MHz
Data rate	10 Mbit/s
	100 Mbit/s
	1 Gbit/s
	2.5 Gbit/s
	5 Gbit/s
	10 Gbit/s
Limiting temperature	-40 ... +70 °C unmoved -10 ... +50 °C moved
Conductor resistance @ 20 °C	≤120 Ω/km

Material properties

Material (cable)	PUR (polyurethane)
Colour (cable)	Yellow



Pushing Performance
Since 1945

Material properties

RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained

Commercial data

Packaging size	1
Net weight	31,500 g
Country of origin	Germany
European customs tariff number	85444290
eCl@ss	27061801 Data and communication cable (copper)