


ED 400

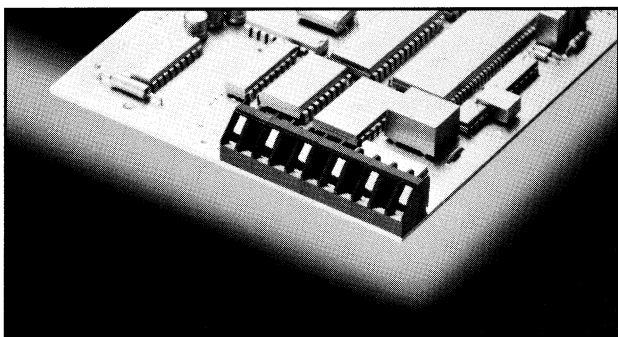

Spacing 10.0 mm
insert required no. of poles ••
How to order see page 6

Ratings:

*Approvals pending



UL1059



CSA 22.2 No. 158



EN 60998

Rated Voltage	250 VB	150 VB	760 V
Rated Current	15 A	7 A	24 A (T60)
Wire Size	AWG 22-12	AWG 22-14	2.5 mm²
Test Voltage			3.5 kV
Rated Torque/Screw Size			0.5 Nm/M2.6

Rated Cross Section

Single Wire (solid)	2.5 mm ²
Stranded Wire (flexible)	1.5 mm ²
Stranded wire with Ferrules	1.5 mm ²

Dimensions

Spacing	10.0 mm
PCB Hole Diameter	1.3 mm
Stripped Length	7.0 mm

Materials

Insulating Material	PA
Flammability Class	UL94 V-0
Temperature Range	-30°C/+105°C
Terminal Block	CuZn
Wire Guard	Cu
Color	Blue

