



My Cart

My Part Lists

Sign In/Register

English (Change)

Have a Question?

Chat with a Product Information Specialist





Products

Industries

Resources

About TE

Support Center

My Account


[Home](#) > [Products](#) > [2mm Centerline](#) > [Product Feature Selector](#) > Product Details

 Share

 Print

 Email

223016-2 Product Details

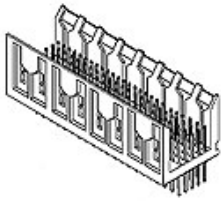

223016-2

(223013-8)

TE Internal Number: 223016-2

 Active

 [View 3D PDF](#)

Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Module Type = Signal
- 60 Signal Positions
- Connector
- Header
- Fixed-Board Application

[View all Features](#)

Add to My Part List

 Request Sample

 Find Similar Products

 Buy Product

Quick Links

- Check Pricing & Availability
- Search for Tooling
- View Mating Products (6)
- Product Feature Selector
- Contact Us About This Product

Documentation & Additional Information

Product Drawings:

- [ASSEMBLY, PIN, SIGNAL, VERTICAL, Z-PACK 2mm FB, 5 RO...](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- [Z-PACK 2 mm FB \(Futurebus+\) Receptacle and Pin Heade...](#) (PDF, English)

Instruction Sheets:

- None Available

CAD Files: (CAD Format & Compression Information)

- [2D Drawing](#) (DXF, Version N)
- [3D Model](#) (IGES, Version N)
- [3D Model](#) (STEP, Version N)

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)
- [Mating Products \(6\)](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Connector
- Connector Type = Header
- [PCB Mounting Orientation](#) = Vertical
- [Post Type](#) = Press-Fit

Mechanical Attachment:

- [Module Type](#) = Signal
- [Mating Post Length \(mm \[in\]\)](#) = 5.75 [0.226]
- Press-Fit Post Style = Compliant Pin
- Pin Header Width (mm [in]) = 18.00 [0.709]

Electrical Characteristics:

- Voltage Rating (VAC) = 30

Termination Features:

- [Termination Post Length \(mm \[in\]\)](#) = 4.25 [0.167]

Contact Features:

- Contact Type = Pin
- Contact Base Material = Phosphor Bronze
- Contact Plating, Mating Area, Material = Gold (30)

Housing Features:

- Connector Style = Plug
- Housing Material = Liquid Crystal Polymer (LCP)

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Conditions for Usage:

- Applies To = Printed Circuit Board

Downloaded from [Arrow.com](#)

[2/2/2012 11:33:22 AM]

Body Features:

- [Number of Signal Positions](#) = 60
- [Sequencing](#) = No
- [Number of Rows](#) = 5
- [Post Plating](#) = Tin Lead over Nickel
- Centerline, Matrix (mm [in]) = 2.00 x 2.00 [.079 x .079]

Operation / Application:

- [Application](#) = Fixed-Board

Other:

- Brand = AMP
- Comment = Sequencing of the mating posts and lead lengths is available. Worksheets for this procedure may be found under Z-PACK 2mm FB General Information.

Corporate Information

- Who We Are
- Investors
- News Room
- Supplier Portal
- Careers

Quick Links

- Check Distributor Inventory
- Cross Reference
- Find Documents & Drawings
- Product Compliance Support Center
- Site Map

Customer Support

- Email or Chat With Us
- Find a Phone Number
- Search Knowledge Base
- Manage your Account

Keep Me Informed

Receive TE News, Events & Technology Updates

