

[Find by Feature](#)
[Browse by Category](#)
[Share](#)
 Search →

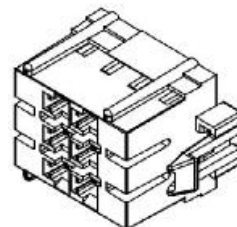
Enter part number or keyword

[Search Results \(1\)](#)
[Search Options](#)

1 Results:

[Compare](#)
12129715 CONN 6 F M/P 280 GRA MD FLXLK

Keyword: 12129715

[Edit Search Options](#)
CONN 6 F M/P 280 GRA MD FLXLK
Part #12129715

[Attributes](#)
[Documents \(6\)](#)
[Related Products \(15\)](#)

Part #:	12129715
Description:	CONN 6 F M/P 280 GRA MD FLXLK
Product Type:	Connector
Status:	Active
Family:	Metri-Pack
Series:	2.8
Cavities:	6
Terminal(s) blade size [mm]:	2.8
Sealed:	Unsealed
Gender:	Female
Temperature range []:	-40 to 125
Material:	Nylon
Weight [g]:	11.18454
Color:	Gray Medium
ELV compliant:	Yes
RoHs compliant:	Yes
Remarks:	for this component, do not use thin stock female terminal (thickness<0.40) with 1.00mm sq. or larger cable. use terminals with tongue guards p/n 15324339 or equivalent.

Certain products listed on this website may be subject to restricted usage or distribution or may not be available. For additional information, please contact your local sales office.