




+ CONNECTORS
HEAT SINKS

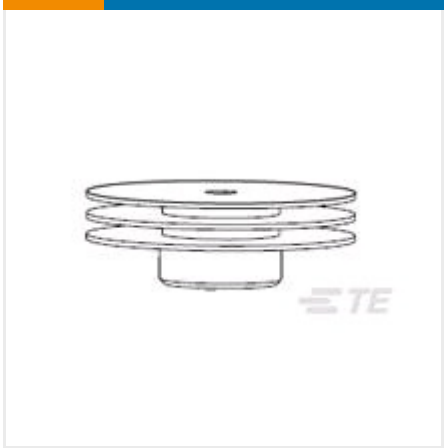

✓ Active

TE CONNECTIVITY (TE)
HTS207-P=25MM HS ASSY PPA CLIP

Thermal Solutions | [HS](#) , [PKA](#)

6-1542000-3
TE Internal Number: 6-1542000-3
Alias ID: HTS207-P

[EU RoHS Compliant with Exemptions](#)
[EU ELV Compliant with Exemptions](#)

Product Type Heat Sink
Device Type BGA
Fin Style Radial
Number of Fins 3
Power (W) 10, 15, 5

[↓](#) **PRODUCT DRAWING**
English

[↓](#) **3D PDF**

DOCUMENTATION

Product Drawings

25mm HS ASS'Y (HTS207-P)
PDF
English

CAD Files

3D PDF
PDF
3D

Customer View Model
2D_DXF.ZIP
English

Customer View Model

3D_IGS.ZIP

English

Customer View Model

3D_STP.ZIP

English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

Product Type Heat Sink

Device Type BGA

Accessory Type Clip

Configuration Features

Number of Fins 3

Electrical Characteristics

Power (W) 10, 15, 5

Body Features

Fin Style Radial

Material Aluminum

Plating Material Black Anodized

Dimensions

Height 11.23 mm [.442 in]

Diameter 34.92 mm [1.375 in]

Width (in) 1.375

Usage Conditions

Thermal Resistance (°C) 10.46, 11.44, 13.23, 3.28, 3.31, 3.45, 3.72, 3.84, 4.05, 5.99, 6.03, 6.04

Operation/Application

For Use With BGA Semiconductor Packages

I/O Pluggable No

Industry Standards

UL Flammability Rating UL 94V-0

Other

Air Velocity (LFM) 0, 200, 400, 600
Comment Heat sink assembly includes Two Leg Standard Clip, Part Number 1542367-1.

PRODUCT COMPLIANCE

+

Statement of Compliance

Statement of Compliance
PDF

