


Pushbutton, Single Pole



S124

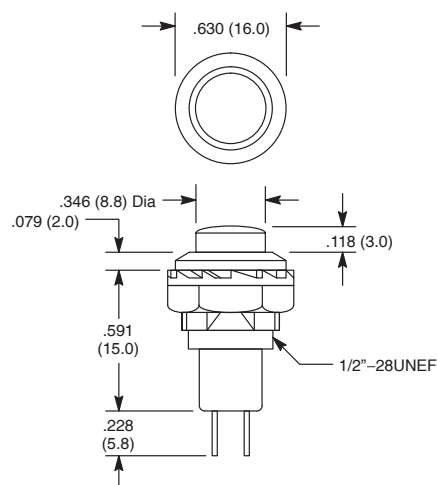

	NTE Type No.	Circuitry	Action	Actuator		Diag No.
				Material	Color	
NEW	54-700-R	SPST	OFF (ON)	Plastic	Red	S124
NEW	54-700-B	SPST	OFF (ON)	Plastic	Black	S124

SPECIAL NOTE: () = Momentary Function

Specifications

Current Rating: 3A 125VAC; 1.5A 250VAC
Insulation Resistance: 100 Megohms (min.) at 500VDC
Dielectric Strength: 1000V RMS (min.), 1 minute
Temperature Rating: -13° to +185°F (-25° to +85°C)
Electrical Life: 6000 cycles
Mechanical Life: 100,000 cycles
Terminal Type: Solder Lug
Mounting Hole: .500 (12.7)


Pushbutton, Single Pole

Features

- Snap-In Mounting, Easy to Install into Panel



S127

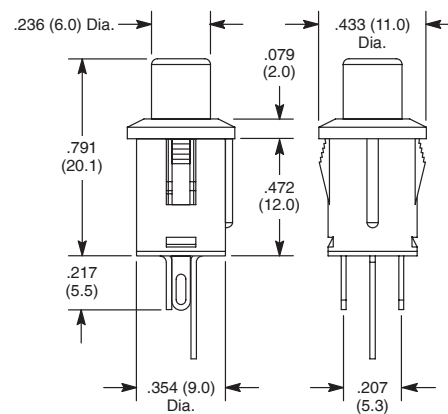

	NTE Type No.	Circuitry	Action	Actuator		Diag No.
				Material	Color	
NEW	54-747-1	SPST	OFF (ON)	PC	Red	S127

SPECIAL NOTE: () = Momentary Function

Specifications

Current Rating: 1A 125VAC; 0.5A 250VAC
Insulation Resistance: 100 Megohms (min.) at 500VDC
Dielectric Strength: 1000VAC, 1 minute
Temperature Rating: -4° to +185°F (-20° to +85°C)
Electrical Life: 6000 cycles
Mechanical Life: 100,000 cycles
Terminal Type: Solder Lug
Mounting Hole: .366 (9.3)