




Quality Products. Service Excellence.

## Hole Plugs *HPN4SS Series*

Type 4X Stainless Steel - UR/cUR

### Features

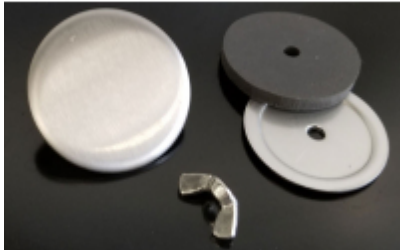

- Designed to seal unused pushbutton holes, conduit openings and knockout holes against dust, oil and water.
- Standard Pushbutton size is 30.5mm
- Available in 8 sizes.
- Finished in brushed natural 304 stainless steel.
- Oil resistant gasket.
- Secured with an 10-24 x 0.55" threaded stud and stainless steel wing nut.
- Recognized component UR & cUR
  - Type 1, 3, 3R, 4, 4X, 12 and 13



Part No.	Description	Max Hole Diameter	Plug Diameter
HP22SSN4	22mm Pushbutton	0.88	1.22
HP50SSN4	.5" Conduit	0.88	1.38
HP75SSN4	.75" Conduit	1.06	1.56
HPBSSN4	30mm Pushbutton	1.25	1.75
HP100SSN4	1" Conduit	1.38	1.88
HP125SSN4	1.25" Conduit	1.69	2.19
HP150SSN4	1.5" Conduit	2.00	2.50
HP200SSN4	2" Conduit	2.50	3.00

Tags: hole plug, type 4X, type 12, NEMA 4X, stainless steel, pushbutton, conduit, knockout *Data subject to change without notice*

© 2026. Hammond Manufacturing Ltd. All rights reserved.