


HDP Series

Micro Mini Side Actuated Surface Mount Detect Switches

Littelfuse® | **C&K**
Switches

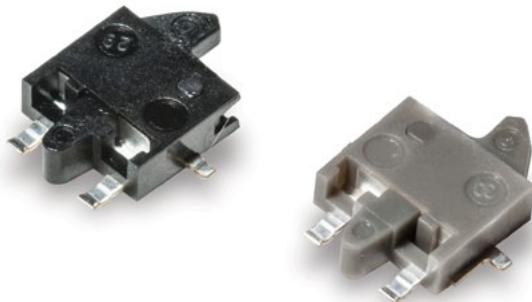

Specifications

Contact Rating	1mA @ 5 VDC	
Operating Life	100,000 cycles min.	
Contact Resistance	< 500 Ω max. initial	
Insulation Resistance	> 100 M Ω	
Operating Temperature	-20°C to 70°C	
Storage Temperature	-30°C to 80°C	
Packaging	Tape & reel; 2,500 per reel	
Travel	Pre-travel	.15 mm min.
	"ON" Starting Position	2.96 +/- 0.25 mm
	Total Travel Position	1.3 mm
	Total Travel	1.9 mm

Ordering Number

Our easy build-a-switch concept allows you to mix and match options to create the switch you need. To order, select desired option from each category and place it in the appropriate box.

HDP - 001 - x

R: Right Actuation
L: Left Actuation

HDP Series

Micro Mini Side Actuated Surface Mount Detect Switches



Littelfuse® | **C&K**
Switches

Complete part numbers for HDP Series are shown below.

HDP001R



Part Number	Packaging	Schematic
HDP001R	Tape & Reel	 N.O.

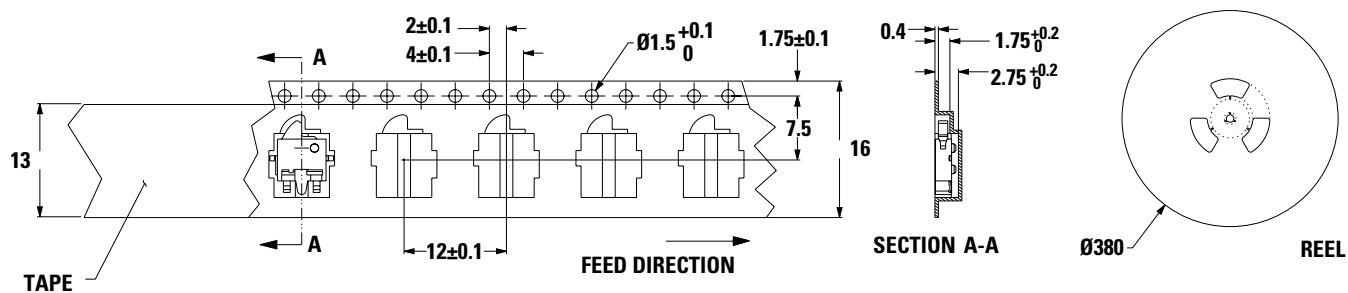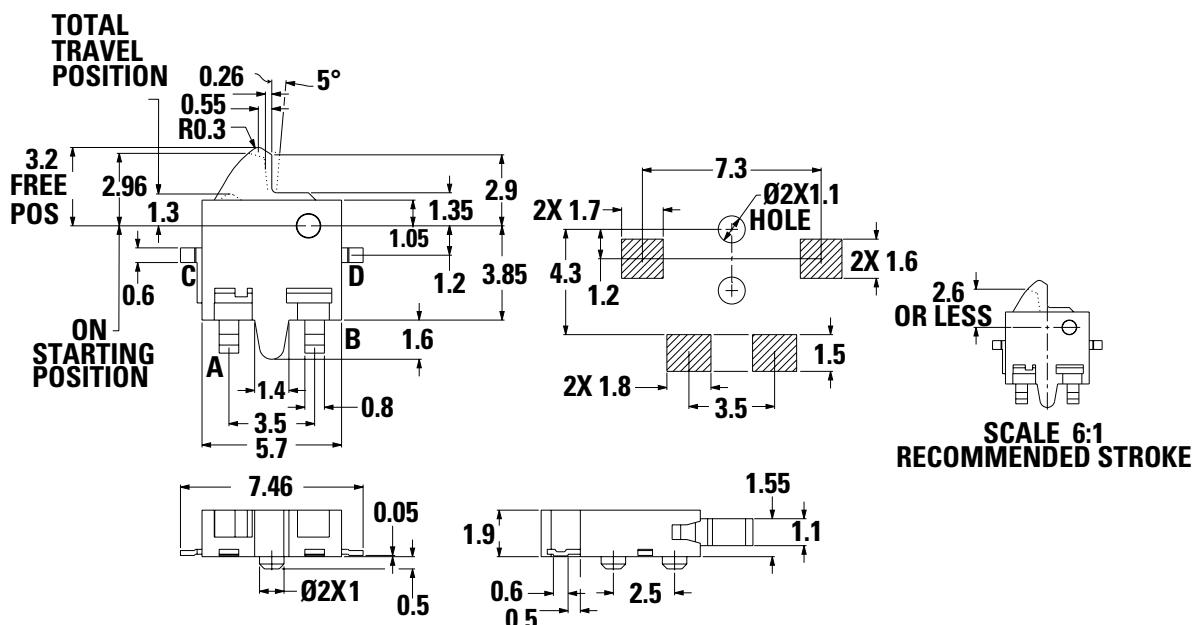


HDP Series



Micro Mini Side Actuated Surface Mount Detect Switches

 **Littelfuse®** | **C&K** Switches

 HDP001L



Part Number	Packaging	Schematic
HDP001L	Tape & Reel	 N.O.

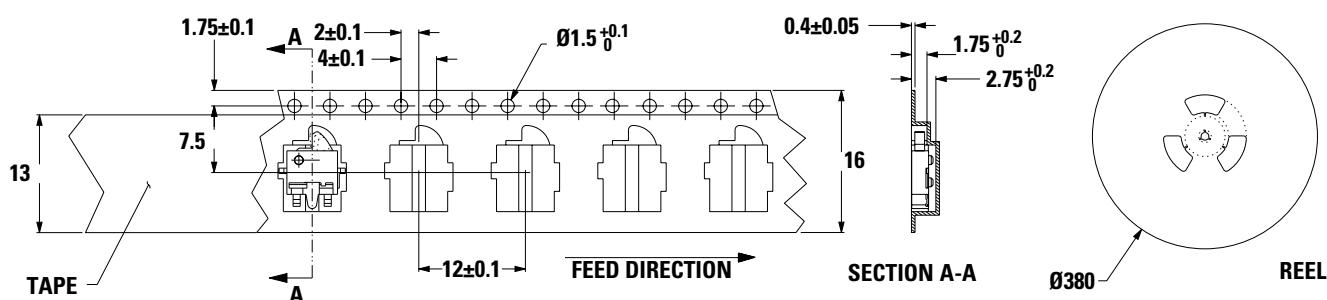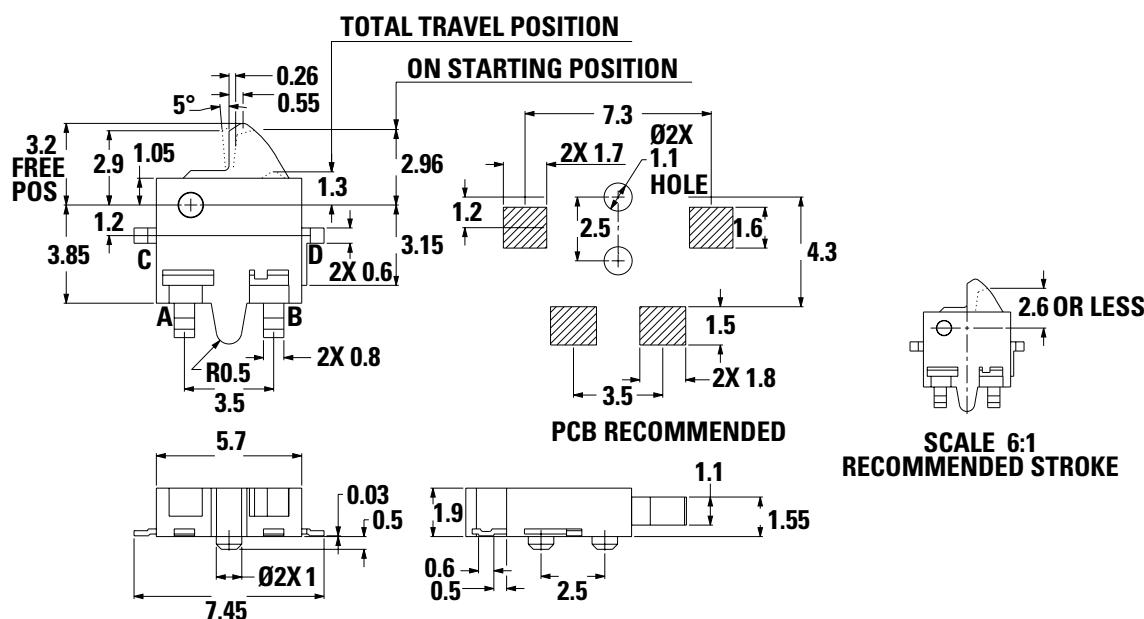

Disclaimer Notice - Information furnished is believed to be accurate and reliable. However, users should independently evaluate the suitability of and test each product selected for their own applications. Littelfuse products are not designed for, and may not be used in, all applications. Read complete Disclaimer Notice at <http://www.littelfuse.com/disclaimer-electronics>.

