




Part Number : [5020782162](#)

Product Description : 0.25mm Pitch Easy-On FPC Connector, 1.00mm Mated Height, Right-Angle, Surface Mount, Bottom Contact Style, with Extended Actuator, 21 Circuits, Halogen-Free, 6000 Pieces per Reel

Series Number : 502078

Status : Active

Product Category : FFC / FPC Connectors

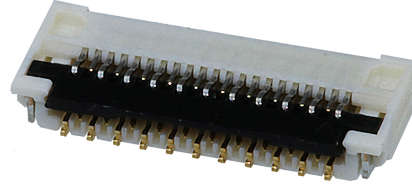

Documents & Resources

Drawings

[Drawing 5020782162_sd.pdf](#)

3D Models and Design Files

[3D Model 5020782162_stp.zip](#)

Specifications

[Packaging Specification 5020789200-200.pdf](#)

[Product Specification 5020780000-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)4144-DC (27 June 2024)
EU RoHS	Compliant per EU 2015/863

[Multiple Part Product Compliance Statements](#)

- Eu RoHS
- REACH SVHC
- Low-Halogen

[Multiple Part Industry Compliance Documents](#)

- IPC 1752A Class C

- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	FFC / FPC Connectors
Series	502078
Description	0.25mm Pitch Easy-On FPC Connector, 1.00mm Mated Height, Right-Angle, Surface Mount, Bottom Contact Style, with Extended Actuator, 21 Circuits, Halogen-Free, 6000 Pieces per Reel
Comments	Black actuator
Product Family	Easy-On FFC FPC Connectors
Product Name	Easy-On
UPC	191128128872

Electrical

Current - Maximum per Contact	0.3A
Voltage - Maximum	50V

Physical

Actuator Type	Front Flip
Circuits (Loaded)	21
Circuits (maximum)	21
Color - Resin	Beige
Contact Position	Bottom
Durability (mating cycles max)	10
Mated Height	1.00mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Gold

Material - Resin	Liquid Crystal Polymer
Net Weight	33.021/mg
Orientation	Right Angle
Packaging Type	Embossed Tape on Reel
PCB Locator	No
PCB Mounting	Surface Mount
PCB Retention	Yes
Pitch - Mating Interface	0.25mm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-40° to +85°C
Wire/Cable Type	FPC only

Mates With / Use With

Mates with Part(s)

Description	Part Number
0.25mm Pitch Premo-Flex FPC Jumpers	<u>15014</u>

This document was generated on Sep 25, 2024