




Color: ■ white

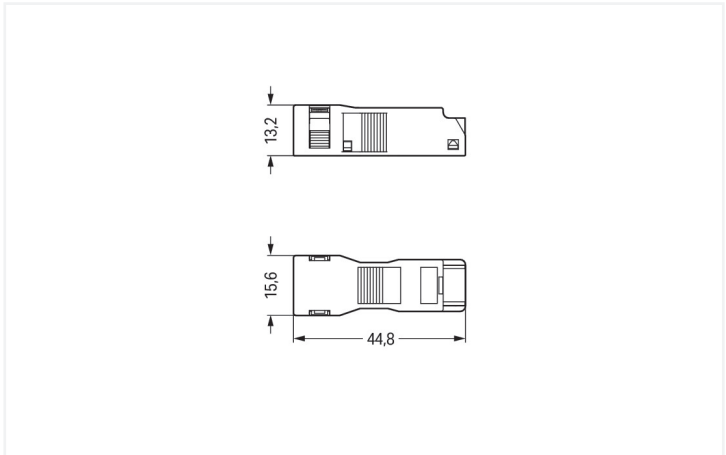

Dimensions in mm

Strain relief housing *WINSTA*® MINI 2-pole

Choose tried-and-tested accuracy for the electrical installation for the implementation of your project: The strain relief housing from the *WINSTA*® MINI product line. An extensive range of accessories complements the *WINSTA*® product line from WAGO. If only limited space is available, our smallest pluggable connection system, *WINSTA*® MINI, consistently displays its advantages. It saves space, and, thanks to Push-in CAGE CLAMP® spring pressure connection technology, it also can be installed quickly, since the connection is low-maintenance and requires no screw connections. A range up to 32 mm can be used for the strip length.

Lower costs through fast commissioning and elimination of service expenses – solutions from *WINSTA*® MINI

The *WINSTA*® Pluggable Connection System allows pluggable electrical installation. This saves time, lowers costs, and reduces the need for servicing. Take advantage of the pluggable version of our maintenance-free spring pressure connection technology too! Plan your installation with with protection against mismatching from WAGO.

- easy tool-free operation, a wide range of coding options
- fast, secure installation

Connection data	
Connection 1	
Pole number	2
Connectable sheathed cable diameter	3.8 ... 8.2 mm
Strip length (outer insulation)	32 mm

Physical data	
Pin spacing	4.4 mm / 0.173 inches
Width	15.6 mm / 0.614 inches
Height	13.2 mm / 0.52 inches
Depth	44.8 mm / 1.764 inches



Material data		
Note (material data)		Information on material specifications can be found here
Color	white	
Insulation material (main housing)	Polyamide (PA66)	
Flammability class per UL94	V0	
Fire load	0.094 MJ	
Weight	2.9 g	

Environmental requirements		
Processing temperature	-5 ... +40 °C	
Continuous operating temperature	-35 ... +85 °C	
Note on continuous operating temperature	Insulating parts for temperatures ≤ 105 °C	

Commercial data		
Product Group	20 (Winsta)	
PU (SPU)	50 pcs	
Packaging type	Box	
Country of origin	DE	
GTIN	4045454233358	
Customs tariff number	39269097900	

Product classification		
UNSPSC	39121421	
eCl@ss 10.0	27-44-06-92	
eCl@ss 9.0	27-44-06-92	
ETIM 9.0	EC002863	
ETIM 8.0	EC002863	
ECCN	NO US CLASSIFICATION	

Environmental Product Compliance		
RoHS Compliance Status	Compliant,No Exemption	

Approvals / Certificates		
General approvals		



Approval	Standard	Certificate Name
cURus Underwriters Laboratories Inc.	UL 1977	E45171



Downloads			
Environmental Product Compliance			
Compliance Search			
Environmental Product Compliance 890-512			↓

Documentation			
Bid Text			
890-512	19.02.2019	xml 2.75 KB	↓
890-512	20.11.2014	doc 23.50 KB	↓

CAD/CAE-Data	
CAD data	CAE data
2D/3D Models 890-512	EPLAN Data Portal 890-512
↓	↓
	WSCAD Universe 890-512
	↓
	ZUKEN Portal 890-512
	↓