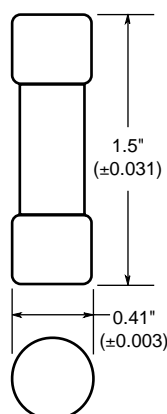


## Fast-Acting Ferrule Fuses

**1 $\frac{3}{32}$ " × 1 $\frac{1}{2}$ " Midget****Dimensional Data**

Catalog Symbol: AGU (5AG)

Fast-Acting

Ampere Rating: 1 to 60 Amperes

No Agency Listings

- Glass tube.
- Nickel plated brass ferrules.

Options:

- Gold plated ferrules

Order number AGU-(amp)-1J0281

**Electrical Ratings (Catalog Symbol and Amperes)**


250 Volts AC		32 Volts AC	
AGU-1	AGU-4	AGU-20	AGU-50
AGU-2	AGU-5	AGU-25	AGU-60
AGU-3	AGU-8	AGU-30	—
—	AGU-10	AGU-35	—
—	AGU-15	AGU-40	—

**Carton Quantity and Weight**

Ampere Ratings	Carton Qty.	Weight	
		Lbs.	Kg.
1-60	100	1.3	0.590

**Recommended Fuseblocks—30 amps maximum**

Poles	Terminal Type		
	Screw With Quick Connect	Pressure Plate w/Quick Connect	Box Lug
1	BM6031SQ	BM6031PQ	BM6031B
2	BM6032SQ	BM6032PQ	BM6032B
3	BM6033SQ	BM6033PQ	BM6033B

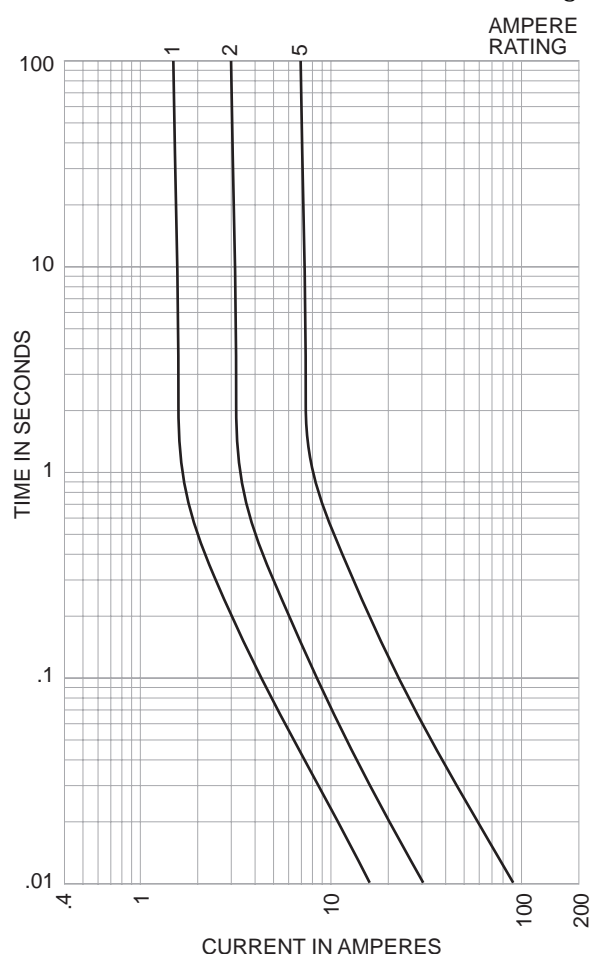**Time-Current Characteristic Curves—Average Melt**

CE CE logo denotes compliance with European Union Low Voltage Directive (50-1000 Vac, 75-1500 Vdc). Refer to BIF document #8002 or contact Bussmann Application Engineering at 314-527-1270 for more information.

The only controlled copy of this BIF document is the electronic read-only version located on the Bussmann Network Drive. All other copies of this document are by definition uncontrolled. This bulletin is intended to clearly present comprehensive product data and provide technical information that will help the end user with design applications. Bussmann reserves the right, without notice, to change design or construction of any products and to discontinue or limit distribution of any products. Bussmann also reserves the right to change or update, without notice, any technical information contained in this bulletin. Once a product has been selected, it should be tested by the user in all possible applications.