


SKS-4N-19

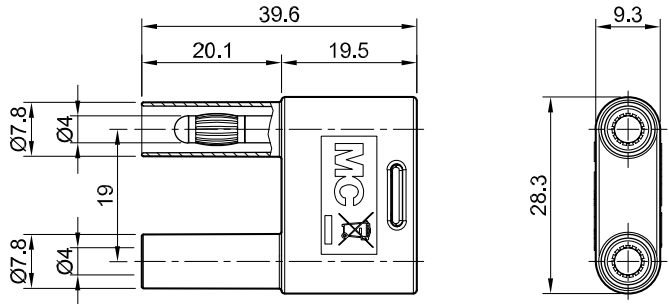

Item number 66.4012-\*

Insulated, Ø 4 mm, made of brass. Plugs with spring-loaded MULTILAM contact technology and rigid insulating sleeves. With insulated grip. At rear without in-line Ø 4 mm rigid sockets.

| Technical data                       |                                   |
|--------------------------------------|-----------------------------------|
| Diameter of plug system              | 4 mm                              |
| Rated Values                         | 1000 V, CAT II, 32 A              |
| Surface treatment electrical contact | Ni                                |
| Base material electrical contact     | CuZn                              |
| Standard color(s) *                  | <div>2021222324252627282930</div> |
| Plug spacing                         | 19 mm                             |
| Test accessory acc. to               | IEC EN 61010-031                  |
| Approvals                            | UL, CE                            |