


KEMET, FLLD4-TH, EMI/RFI Filters, Noise Suppression, 530 VAC, 8 A, 120x115x80mm

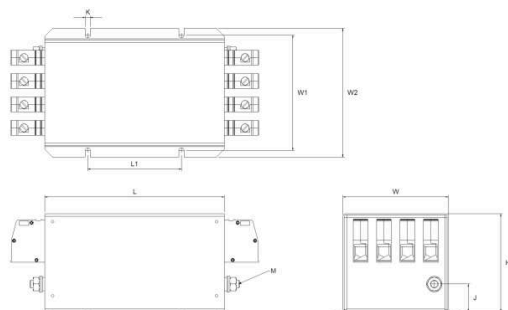

General Information

Series:	FLLD4-TH
Style:	Chassis Mount
Description:	EMI Filter, Classis Mount, Compact
Features:	High Performance
Phase:	Three-phase + Neutral
RoHS:	Yes
Qualifications:	IEC/EN 60939
Terminal Type:	Terminal Block

Dimensions

L	120mm NOM
W	115mm NOM
H	80mm NOM
L1	80mm NOM
W1	127.5mm NOM
W2	143mm NOM
J	32mm NOM
K	6.5mm NOM
M (Earth)	Threaded Studs M6

Specifications

Voltage AC:	530 VAC
Rated Frequency:	50-60 Hz
Rated Current:	8 A (50°C)
Rated Temperature:	50°C
Temperature Range:	-25/+100°C
Climate Category:	25/100/21
Test Voltage DC (P to P):	2250 VDC
Test Voltage DC (P to E):	3000 VDC
Power Loss:	3 W (25°C 50 Hz)
Leakage Current:	11 mA

Packaging Specifications

Packaging:	Bulk
Packaging Quantity:	1
Component Weight:	800 g