



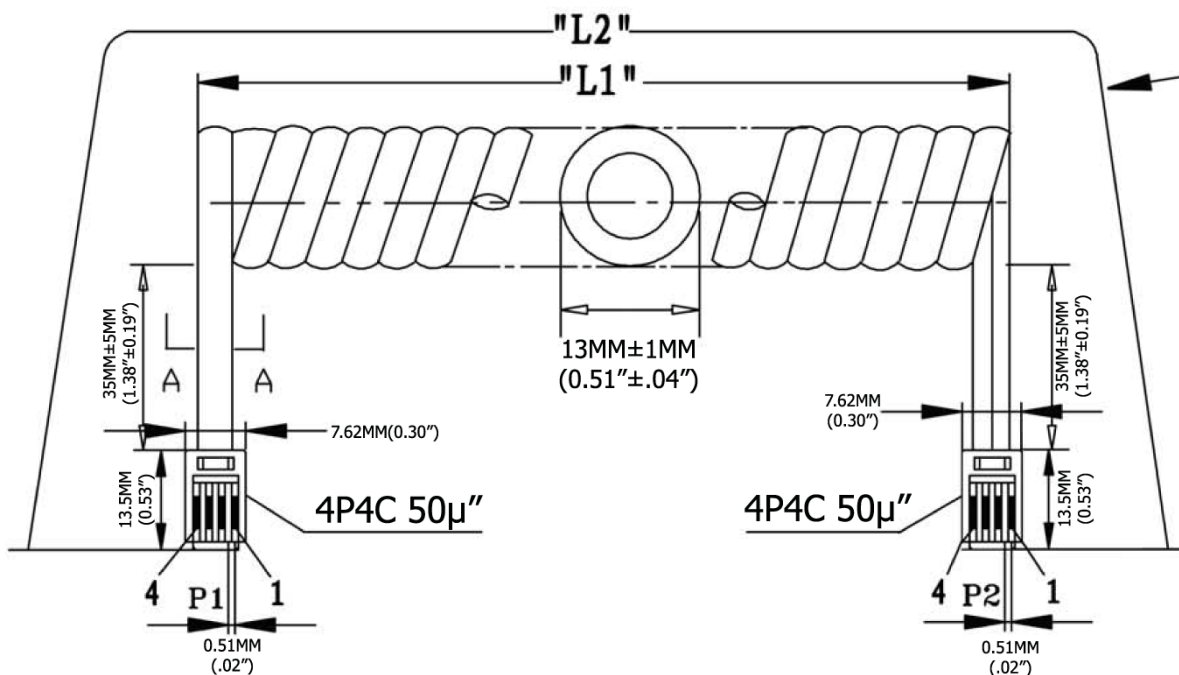

Extended length is with 500g of force

Materials:

- Plug Housing: Polycarbonate, clear
- Plug Terminal: 0.36\"[.014MM] Thick Phosphor Bronze
- Connector: 50μ\" of Selective Gold Contact Plating
 - Area, Gold flash over the remainder
 - Over 2.54μm[.000100] thick nickel underplate
- Conductor(X4C): 26AWG (0.12X12) Bare Copper
- Insulation(X4C): PP6331 ID 0.95-1.0
- Jacket: PVC NOUL 80P
- Package: Individual PE Bag

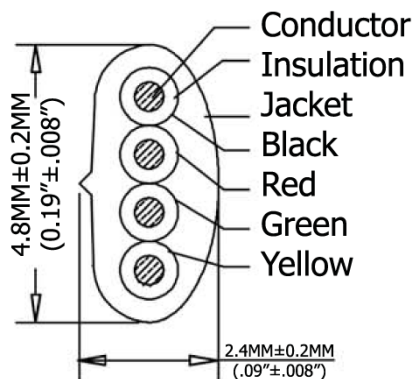

SEC:A-A

TERMINATION:

P1	P2	COLOR
1	1	BLACK
2	2	RED
3	3	GREEN
4	4	YELLOW

Extended Length ("L2")	Typical Retracted Length ("L1")
144.0 Inches - 165.6 Inches	32.0 Inches
3,657.6MM-4,206.24MM	812.8MM

RoHS
Compliant

ITEM NO

AT-C-26-4/4/B-12/R

TITLE NON-UL 26AWG (0.16/7)*4C, O.D.: 2.4*4.8MM
Reverse Plug, 50μ\" of contact plating, BLACK

ASSMANN
Electronics, Inc.

1840 W. Drake Drive, Suite 101 - Tempe, AZ 85283

Toll Free: 1-877-277-6266 Email: info@usa-assmann.com

THIS DRAWING IS UNPUBLISHED
© Copyright 2009 by Assmann Electronic Components
All International Rights Reserved