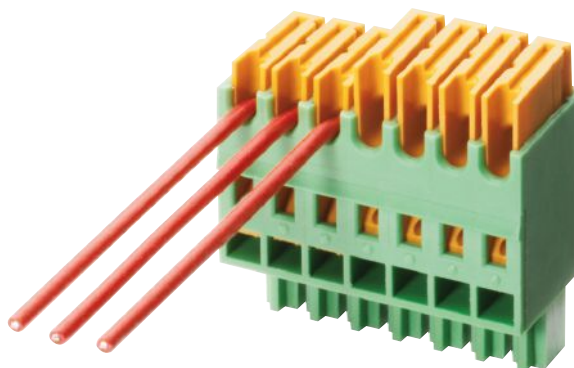


Series EM3583**EuroMag Terminal Blocks**

IDC Pluggable Block

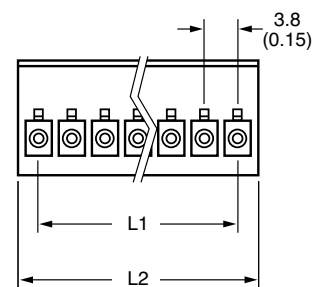
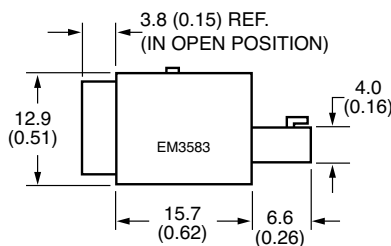
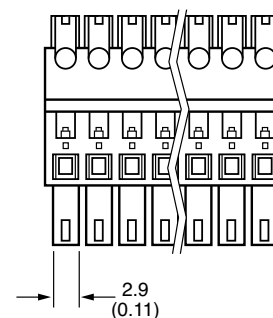
(Mates with EM3593 Series); 3.81 Centers

SPECIFICATIONS**Ratings:** 10A, 160V**Center Spacing:** 0.15" (3.81mm)**Wire Range:** #18-20 AWG**Housing Material:** UL rated 94V0 Thermoplastic**Contact Material:** Brass, Tin-Plated**Operating Temperature:** 105°C (221°F) max., -49°C (-40°F) min.**Construction:** Mold-to-length.**Agency Information:** cULus File E62622; CE Certified

EM358307

Dimensions - mm (in)

Poles	L1 (mm)	L2 (mm)	Poles	L1 (mm)	L2 (mm)
02	3.81	8.40	08	26.67	31.26
03	7.62	12.21	09	30.48	35.07
04	11.43	16.02	10	34.29	38.88
05	15.24	19.83	11	38.10	42.69
06	19.05	23.64	12	41.91	46.50
07	22.86	27.45			

**Part Numbering System**

Inches (Millimeters)

Series**EM3583****# of Positions****02 to 12****Mating Header:** EM3593 pg. 81