



Cable Clamps, Self-Aligning

Features

- Secures the Routing of Cables, Harnesses, and Hoses
- Rounded Edges Protect Against Insulation Abrasion and Cutting Hoses
- Saddle Washer Allows for Quick and Secure Alignment
- Manufactured from Durable and Flexible Nylon 66
- Available in Natural or UV Black

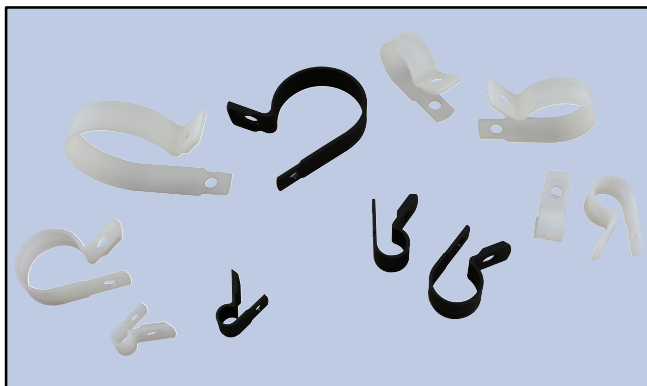

CC-04

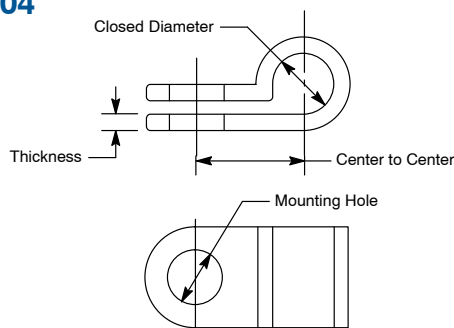

Color Code Chart

0	Black	9	Natural
---	-------	---	---------

Cable Clamps (100 per bag)

NTE Type No.	Screw Size	Width (in. / mm)	Thickness (in. / mm)	Closed Diameter (in. / mm)	Center to Center (in. / mm)	Overall Length (in. / mm)	Diag No.
04-SACL125x	#6	.377 / 9.57	.046 / 1.16	.082 / 2.08	.314 / 7.97	.800 / 20.32	CC-04
04-SACL187x	#6	.377 / 9.57	.049 / 1.24	.151 / 3.83	.362 / 9.19	.867 / 22.02	CC-04
04-SACL250x	#6	.396 / 10.05	.049 / 1.24	.205 / 5.20	.409 / 10.38	.900 / 22.86	CC-04
04-SACL312x	#6	.396 / 10.05	.049 / 1.24	.256 / 6.50	.440 / 11.17	.982 / 24.94	CC-04
04-SACL375x	#10	.486 / 12.34	.057 / 1.44	.352 / 8.94	.492 / 12.49	1.117 / 28.37	CC-04
04-SACL500x	#10	.486 / 12.34	.057 / 1.44	.470 / 11.93	.582 / 14.78	1.233 / 31.31	CC-04
04-SACL625x	#10	.486 / 12.34	.060 / 1.52	.564 / 14.32	.622 / 15.79	1.335 / 33.90	CC-04
04-SACL750x	#10	.469 / 11.91	.060 / 1.52	.693 / 17.60	.708 / 17.98	1.460 / 37.08	CC-04
04-SACL875x	#10	.469 / 11.91	.057 / 1.44	.813 / 20.65	.767 / 19.48	1.577 / 40.05	CC-04
04-SACL1000x	#10	.469 / 11.91	.057 / 1.44	.890 / 22.60	.820 / 20.82	1.684 / 42.77	CC-04
04-SACL1250x	#10	.469 / 11.91	.065 / 1.65	1.126 / 28.60	.940 / 23.87	2.000 / 50.80	CC-04
04-SACL1500x	#10	.486 / 12.34	.060 / 1.52	1.440 / 36.57	.980 / 24.89	2.168 / 55.06	CC-04

Note 1. Replace "x" in device number with corresponding color code from the "Color Code Chart".