

[← BACK TO KNOBS](#)

OES Series





The OES model knob is the OED knob with a skirt. The indicator mark is located on the top of the knob. Indicator options include an arrow or line. Single 6-32 set screw.


PART NUMBER BREAK DOWN

EXAMPLE: OESA-90-4-7

OES	A	90	4	7
MODEL	INDICATOR	DIAMETER	FINISH	SHAFT SIZE
These letters are the model series name.	This value represents the the indication mark*.	This value indicates the outer diameter sizing of the knob.	This value indicates the color and finish of the knob.	This value indicates shaft sizing.
	L - LINE INDICATOR	50 - .500	1 - CLEAR GLOSS	5 - .250
	A - ARROW INDICATOR	63 - .625	2 - BLACK GLOSS	6 - .125
		75 - .750	3 - CLEAR MATTE	7 - .2375 (6MM)
		90 - .925	4 - BLACK MATTE	

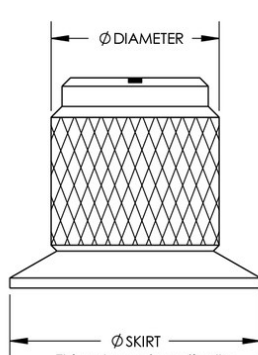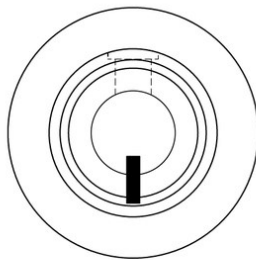

This value automatically determined when diameter is selected.
 50 - .742
 63 - .860
 75 - .995
 90 - 1.250

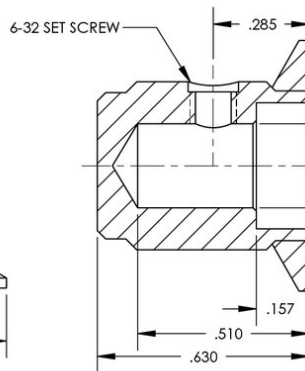

Ø COUNTERBORE
 This value automatically determined when diameter is selected.
 50 - .375
 63 - .500
 75 - .590
 90 - .708

ROHS & REACH COMPLIANCE

CONFLICT MINERALS COMPLIANCE

SPEC PRINTS

"WE COULD MAKE A REALLY BIG KNOB ... WE JUST CHOOSE NOT TO."

© 2016 KILO INTERNATIONAL