

HSF RoHS

SPECIFICATIONS

Rated Current:1.0AMP

Contact Resistance:20mΩ Max

Withstand Voltage:1000V AC/DC

Insulation Resistance:1000MΩ Min


Operation Temperature:-40°c to +105°c

Contact Material:Phosphor Bronze

 
Contact Plating:Au or Sn Over Ni

Insulator Material:Polyester(UL94V-0)

Standard: PPS

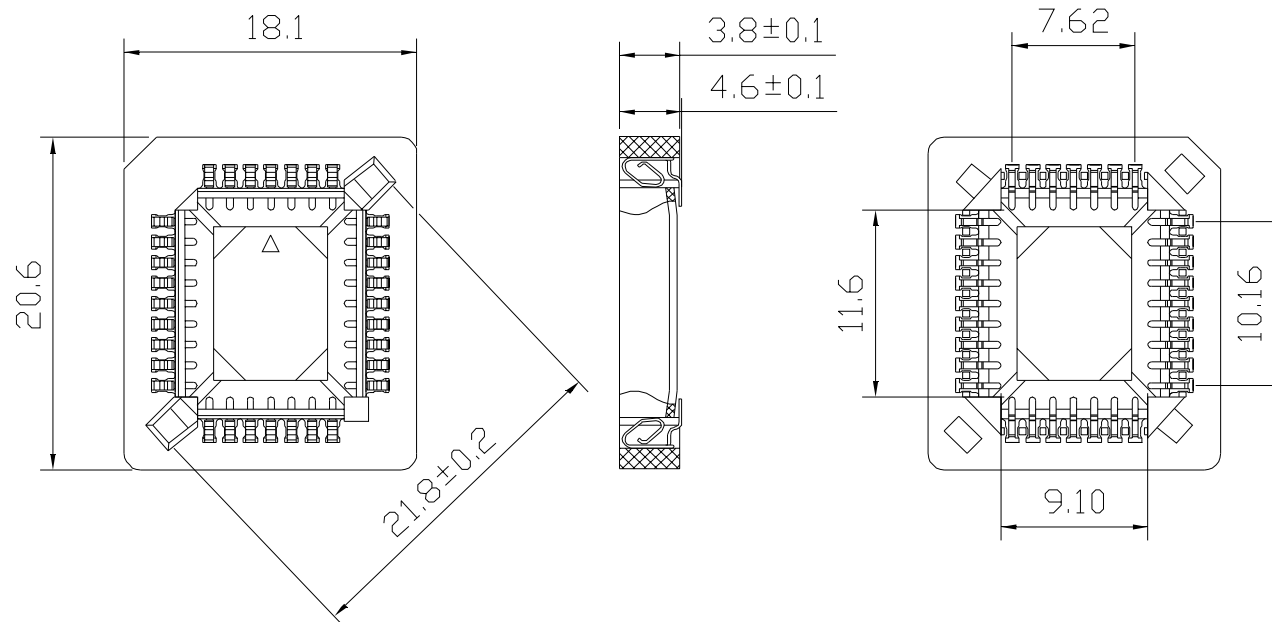

No. of PINs	Tape&Reel Packing
SMT - 32P	500PCS/Reel, 2.5K PCS/Cartron

2014/06/06	Jody		Structural changes		A1
2012/03/06	XIE		NEW DWG		A0
DATE	DR.BY	ECN.NO.	DESCRIPTION	MARK	VER.
-TOLERANCES- UNLESS OTHERWISE SPECIFIED			CnC Tech,LLC  TITLE: PLCC 0.20 SMT 成品		
X.X	±0.30	X.X°	±3.00°	APPD:	PRODUCT NO: 232-XX
X.XX	±0.20	X.XX°	±1.00°	CHECK:	DATE SCALE UNIT TYPE PAGE
X.XXX	±0.15	X.XXX°	±0.500°	DRAW:	2012/04/06 1:1 mm Z 1/1