


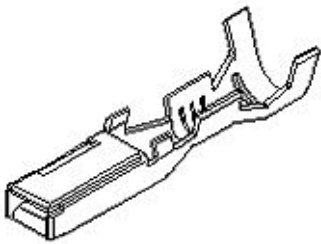

Part Number : 354076102  
Product Description : 2.28mm Terminal, Female, 0.3-0.5 AVSS, 0.25mm Thickness, Pre-Tin Plated  
Series Number : 35407  
Status : Obsolete  
Product Category : Crimp Terminals



Documents & Resources

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 44; 34
China RoHS	Not Relevant
EU ELV	Compliant per 2000/53/EC
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Obsolete
--------	----------

Category	Crimp Terminals
Series	35407
Description	2.28mm Terminal, Female, 0.3-0.5 AVSS, 0.25mm Thickness, Pre-Tin Plated
Application	Power
Product Name	N/A
UPC	756054280386

## Physical

Gender	Female
Material - Metal	High Performance Alloy (HPA)
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.293/g
Packaging Type	Reel
Plating min - Mating	0.813µm
Plating min - Termination	0.813µm
Termination Interface Style	Crimp or Compression
Wire Insulation Diameter	1.90mm max.
Wire Size (AWG)	20, 22
Wire Size mm <sup>2</sup>	N/A

---

This document was generated on Mar 03, 2025