



Part Number : [1300660111](#)


Product Description : BradPower D-Size (1 3/8"-M35) Receptacle, 3 Poles, Female, 1/2" - 14 NPT, 10 AWG, 1.0m (3.28') Length

Series Number : 130066

Status : Active

Product Category : Circular Industrial Connectors

Engineering Part Number : CR3000A30M010

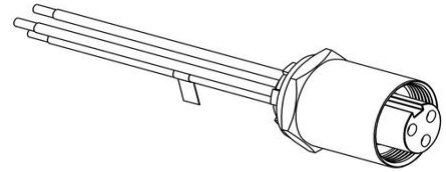


Documents and Resources

Drawings

[1300660111_sd.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant with Exemption 6(c) per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474

- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

CE - Declaration of Conformity

UKCA - Declaration of Conformity

Part Details

General

Status	Active
Category	Circular Industrial Connectors
Series	130066
Description	BradPower D-Size (1 3/8"-M35) Receptacle, 3 Poles, Female, 1/2" - 14 NPT, 10 AWG, 1.0m (3.28') Length
IP Rating	IP67
Product Name	BradPower D-Size
Type	Single Ended (pigtail)
UPC	78678857703

Agency

UL	E258922
----	---------

Electrical

Current - Maximum per Contact	32.0A
Voltage - Maximum	600V AC/DC

Physical

Coupling Type	Internal Thread
Gender	Female
Keyway	Single
Length	1.0m
Material - Component	Clear Anodized Aluminum
Mounting Thread Size	1/2" - 14 NPT

Net Weight	144.000/g
Orientation	Straight
Panel Mount	Front
Poles	3
Temperature Range - Operating	-20° to +90°C
Wire/Cable Type	UL 1015
Wire Size (AWG)	10

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

This document was generated on Jun 02, 2026