

HC-D 25-I-CT-F-Z - Contact insert

1411481

<https://www.phoenixcontact.com/us/products/1411481>



Please be informed that the data shown in this PDF document is generated from our Online Catalog. Please find the complete data in the user documentation. Our General Terms of Use for Downloads are valid.



HEAVYCON socket insert, D25 series, 25-pos., crimp connection, with special printing (row C pos. 1 is printed with the letter Z)

Commercial Data

Item number	1411481
Packing unit	1 pc
Minimum order quantity	1 pc
Sales Key	BF61
Product Key	BF7ABE
Catalog Page	Page 523 (C-2-2019)
GTIN	4046356921831
Weight per Piece (including packing)	34.8 g
Weight per Piece (excluding packing)	33 g
Customs tariff number	85389099
Country of origin	CN

HC-D 25-I-CT-F-Z - Contact insert



1411481

<https://www.phoenixcontact.com/us/products/1411481>

Technical Data

Notes

General	For HEAVYCON housing type D25, CK1,6-ED crimp contacts (crimp contacts not supplied as standard)
General	Connectors may be operated only when there is no load/voltage.
General	It is imperative that guide pins (HC-CST) and sockets (HC-CBU) are used to prevent tip collision due to misalignment.

Mounting

Assembly instructions	To ensure correct use, installation in housing with IP54 protection or better is required
-----------------------	---


Product properties

Type	D25
	D50
Product type	Contact insert with a fixed no. of positions
Number of positions	25
Note number of positions	25+PE
Connection profile	25+PE
Contact type	turned
Series	HC-D

Insulation characteristics

Overvoltage category	III
Degree of pollution	3

Dimensions

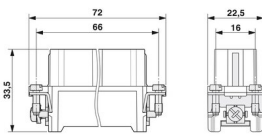Dimensional drawing	
Width	22.5 mm
Height	33.5 mm
Length	72 mm
Drill hole distance, horizontal	66 mm
Drill hole distance, vertical	16 mm

Mechanical characteristics

Contact diameter	1.6 mm
------------------	--------

Connection data

Connection technology

Connection technology	Crimp connection
-----------------------	------------------

HC-D 25-I-CT-F-Z - Contact insert



1411481

<https://www.phoenixcontact.com/us/products/1411481>

Connection in acc. with standard	IEC / EN
----------------------------------	----------

Conductor connection

Conductor cross section	0.14 mm ² ... 2.5 mm ²
Connection cross section AWG	26 ... 14
Tightening torque	0.7 Nm ... 1 Nm (PE connection) 0.5 Nm ... 0.8 Nm (Mounting screws for mounting in the HEAVYCON housing)
Stripping length of the individual wire	8 mm

Electrical properties

Rated voltage (III/3)	250 V
Rated surge voltage	4 kV
Rated current	10 A
SCCR	5 kA (UL 2237)

Mechanical properties

Mechanical data

Insertion/withdrawal cycles	≥ 500
-----------------------------	-------

Material specifications

Flammability rating according to UL 94	V0
Contact material	Copper alloy
Contact surface material	Ag (alternatively Au)
Contact carrier material	PC
Standards/regulations	PC: Fire protection in rail vehicles - requirement sets R22, R23, and R24 acc. to DIN EN 45545-2 (Risk level HL1 - HL3)

Environmental and real-life conditions

Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C (including heating up of contacts)
---------------------------------	--

Standards and regulations

Constructional and testing regulations	DIN VDE 0627/86
	DIN VDE 0110/02.79
	DIN VDE 0110-1/04.97
	IEC 60664-1, DIN IEC 60512
	IEC 60352
Tests	DIN VDE 0627/86
	DIN VDE 0110/02.79
	DIN VDE 0110-1/04.97
	IEC 60664-1, DIN IEC 60512
	IEC 60352

Testing

HC-D 25-I-CT-F-Z - Contact insert



1411481

<https://www.phoenixcontact.com/us/products/1411481>

Standards/regulations

PC: Fire protection in rail vehicles - requirement sets R22, R23, and R24 acc. to DIN EN 45545-2 (Risk level HL1 - HL3)


HC-D 25-I-CT-F-Z - Contact insert



1411481
<https://www.phoenixcontact.com/us/products/1411481>


Drawings

Dimensional drawing

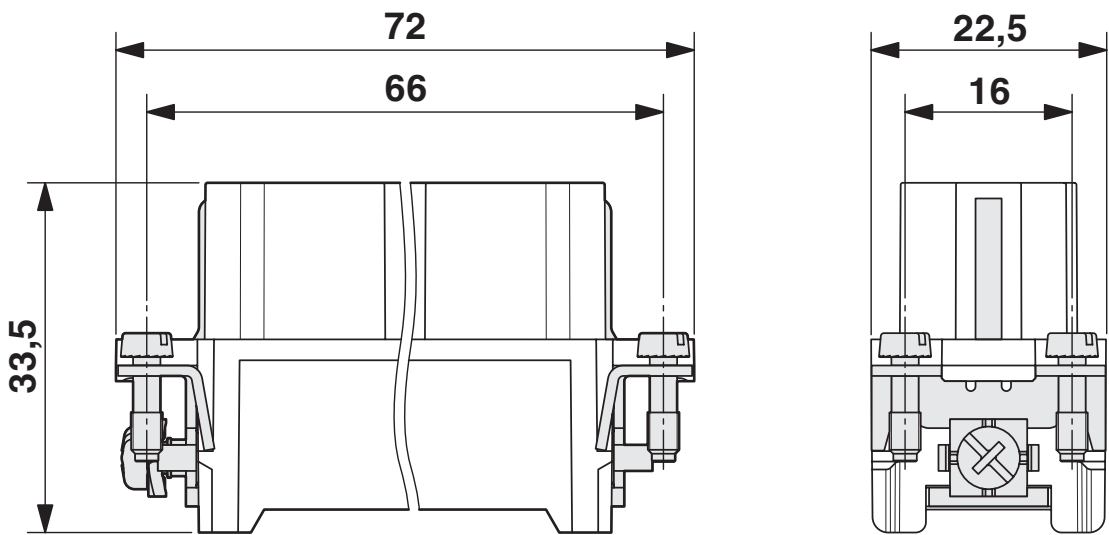

Female insert

Diagram

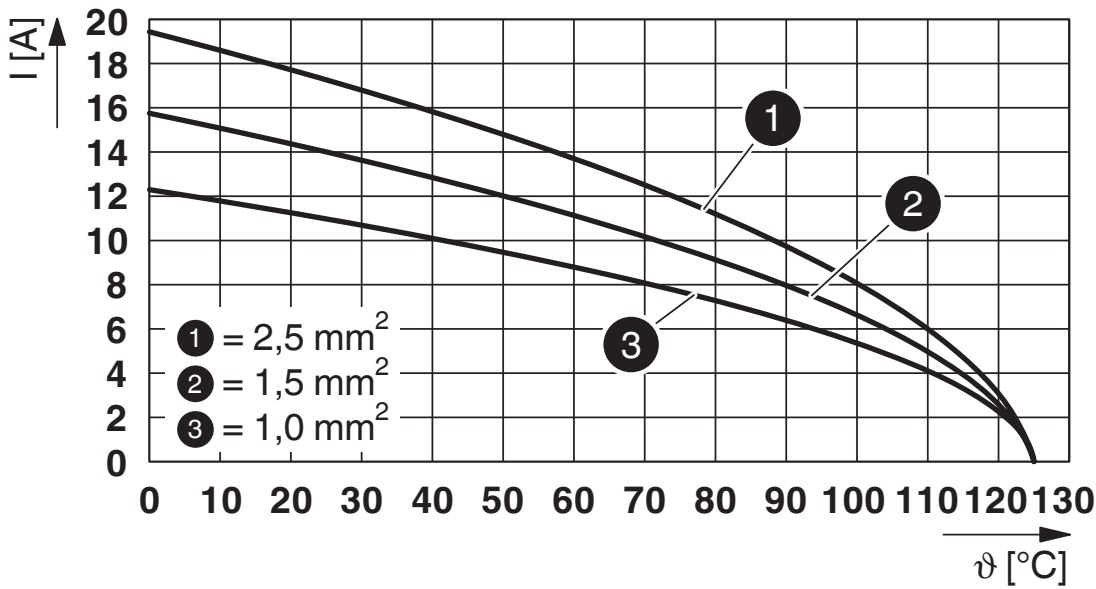

Derating diagram turned contacts


HC-D 25-I-CT-F-Z - Contact insert



1411481

<https://www.phoenixcontact.com/us/products/1411481>

Schematic diagram

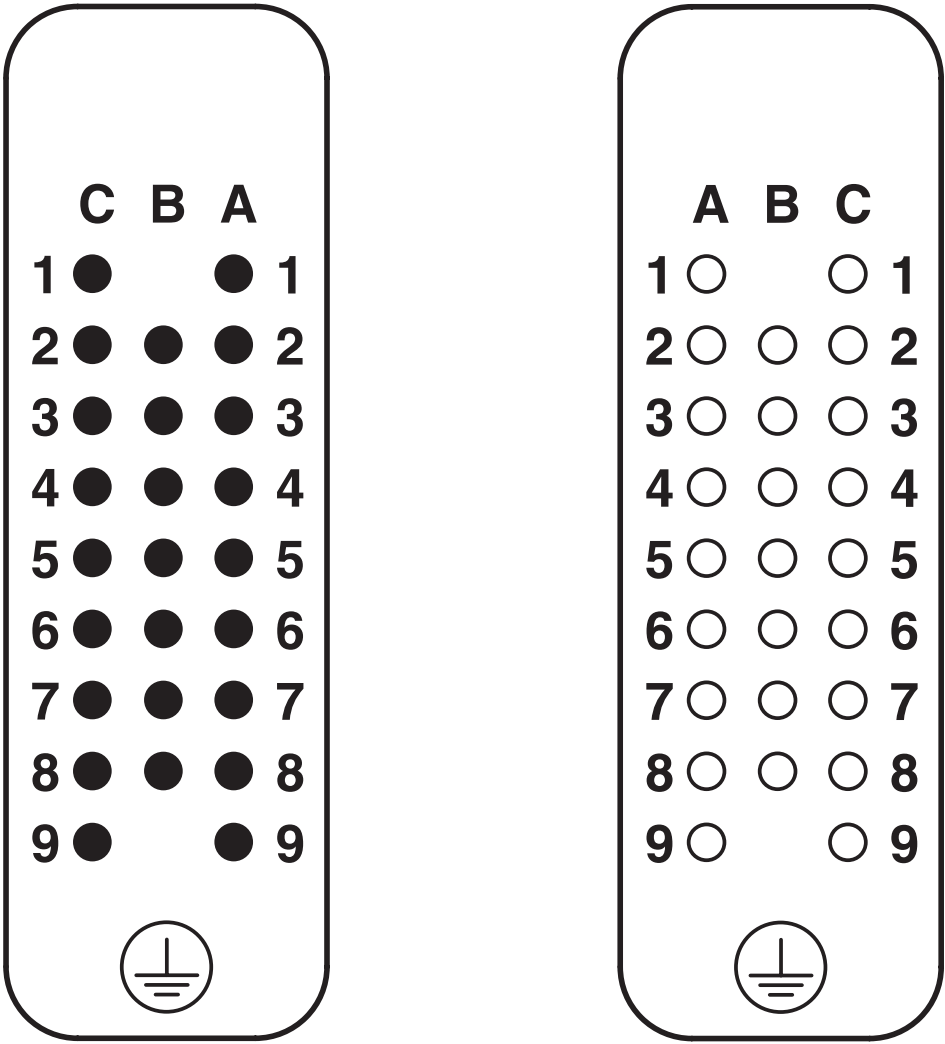

Connector pin assignment connection side: Left pin; right socket


HC-D 25-I-CT-F-Z - Contact insert



1411481


<https://www.phoenixcontact.com/us/products/1411481>

Dimensional drawing

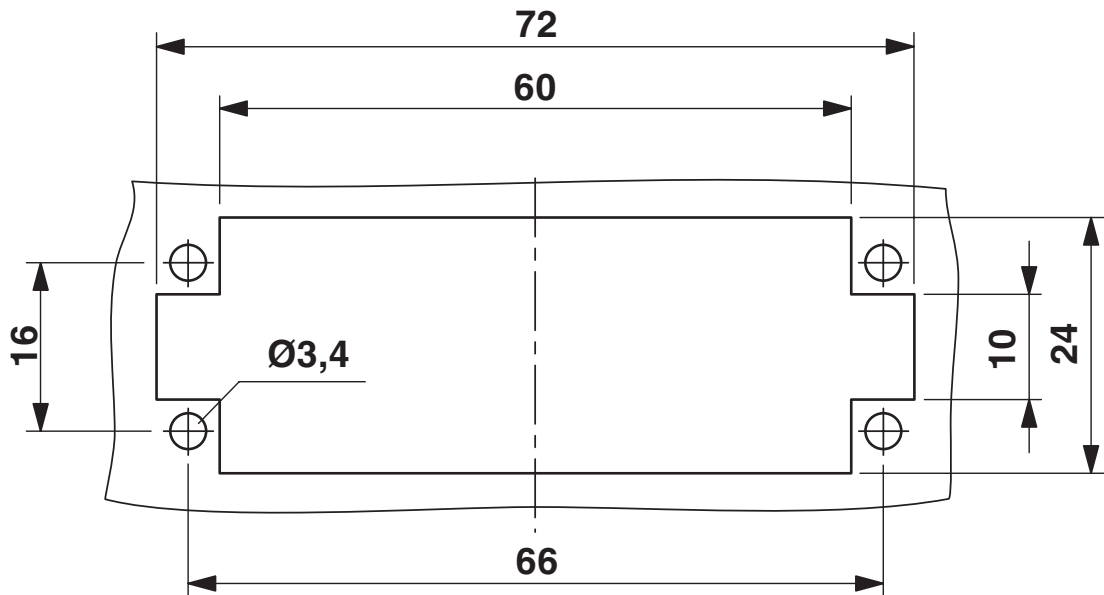

Mounting cutout when used without housing

Diagram

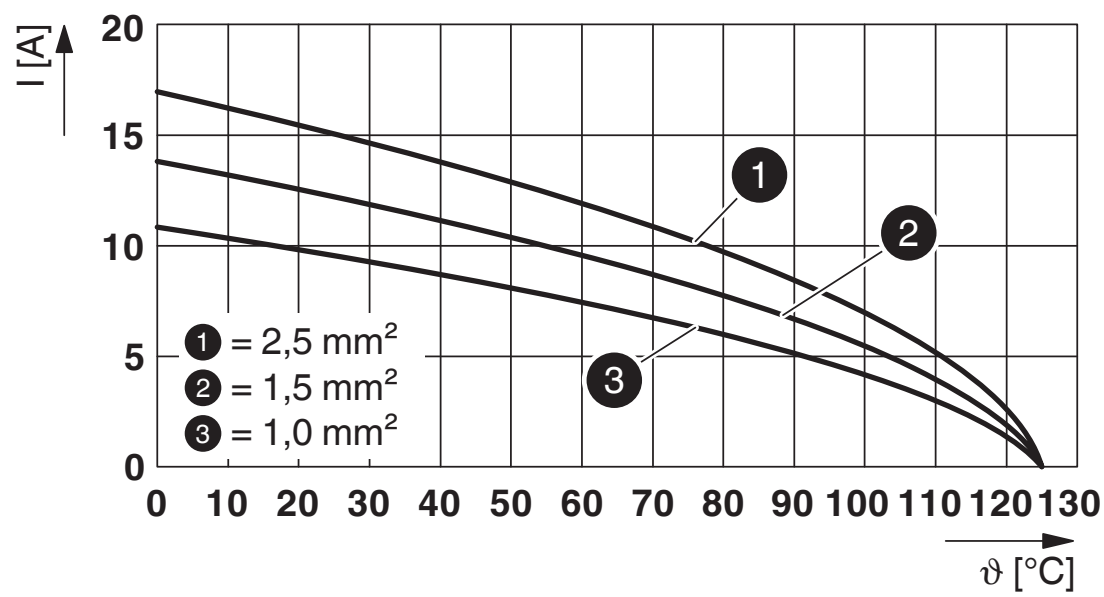

Derating diagram rolled contacts

HC-D 25-I-CT-F-Z - Contact insert



1411481

<https://www.phoenixcontact.com/us/products/1411481>

Approvals

DNV

Approval ID: TAE000037S



CSA

Approval ID: 13631

	Nominal Voltage U_N	Nominal Current I_N	Cross Section AWG	Cross Section mm^2
	600 V	8 A	- 14	-



UL Recognized

Approval ID: FILE E 118976

	Nominal Voltage U_N	Nominal Current I_N	Cross Section AWG	Cross Section mm^2
	600 V	10 A	-	-



EAC

Approval ID: RU C-DE.AI30.B.01102



UL Recognized

Approval ID: E468743

	Nominal Voltage U_N	Nominal Current I_N	Cross Section AWG	Cross Section mm^2
	600 V	10 A	-	-



EAC

Approval ID: RU C-DE.BL08.B.00511

HC-D 25-I-CT-F-Z - Contact insert



1411481

<https://www.phoenixcontact.com/us/products/1411481>

Classifications

ECLASS

ECLASS-9.0	27440205
ECLASS-10.0.1	27440205
ECLASS-11.0	27440205
ECLASS-12.0	27440205
ECLASS-13.0	27440205

ETIM

ETIM 8.0	EC000438
----------	----------

UNSPSC

UNSPSC 21.0	39121500
-------------	----------

HC-D 25-I-CT-F-Z - Contact insert



1411481

<https://www.phoenixcontact.com/us/products/1411481>

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

HC-D 25-I-CT-F-Z - Contact insert

1411481

<https://www.phoenixcontact.com/us/products/1411481>



Accessories

HC-CP-CK1.6-PL - Coding element

1095422

<https://www.phoenixcontact.com/us/products/1095422>

Coding element for HC-D and HC-DD contact inserts with pole loss. Installed in the socket contact chamber.



HC-CB - Coding bolt

1772722

<https://www.phoenixcontact.com/us/products/1772722>

Coding pin, prevents mismatching of up to six connectors with an identical number of positions



HC-D 25-I-CT-F-Z - Contact insert

1411481

<https://www.phoenixcontact.com/us/products/1411481>



HC-CST - Coding element

1676857

<https://www.phoenixcontact.com/us/products/1676857>



Coding peg for coding up to 16 connectors

HC-CBU - Coding element

1676860

<https://www.phoenixcontact.com/us/products/1676860>



Coding socket for coding up to 16 connectors

HC-D 25-I-CT-F-Z - Contact insert

1411481

<https://www.phoenixcontact.com/us/products/1411481>



HC-A-PES - Screw

1584868

<https://www.phoenixcontact.com/us/products/1584868>

PE screw for contact inserts of A series



UNIFOX MT-CK 1.6/2.5 - Assembly tool

1089092

<https://www.phoenixcontact.com/us/products/1089092>

Assembly tool, for CK 1.6... crimp contacts for small conductor cross sections



HC-D 25-I-CT-F-Z - Contact insert

1411481

<https://www.phoenixcontact.com/us/products/1411481>



UNIFOX RT-CK 1.6 - Contact removal tool

1072069

<https://www.phoenixcontact.com/us/products/1072069>

Contact removal tool, for turned and rolled CK- 1.6-... contacts



CK1,6-ED-0,37BU AG - Crimp contact

1663394

<https://www.phoenixcontact.com/us/products/1663394>

Crimp contact, contact diameter: 1.6 mm, turned, Socket, contact material: Copper alloy, contact surface: silver-plated, connection cross section: 0.14 mm² ... 0.37 mm², AWG 26 ... 22



HC-D 25-I-CT-F-Z - Contact insert

1411481

<https://www.phoenixcontact.com/us/products/1411481>



CK1,6-ED-0,50BU AG - Crimp contact

1663404

<https://www.phoenixcontact.com/us/products/1663404>



Crimp contact, contact diameter: 1.6 mm, turned, Socket, contact material: Copper alloy, contact surface: silver-plated, connection cross section: 0.5 mm² ... 0.5 mm², AWG 20

CK1,6-ED-0,75BU AG - Crimp contact

1663417

<https://www.phoenixcontact.com/us/products/1663417>



Crimp contact, contact diameter: 1.6 mm, turned, Socket, contact material: Copper alloy, contact surface: silver-plated, connection cross section: 0.75 mm² ... 0.75 mm², AWG 18

HC-D 25-I-CT-F-Z - Contact insert

1411481

<https://www.phoenixcontact.com/us/products/1411481>



CK1,6-ED-1,00BU AG - Crimp contact

1663420

<https://www.phoenixcontact.com/us/products/1663420>



Crimp contact, contact diameter: 1.6 mm, turned, Socket, contact material: Copper alloy, contact surface: silver-plated, connection cross section: 1 mm² ... 1 mm², AWG 18

CK1,6-ED-1,50BU AG - Crimp contact

1663433

<https://www.phoenixcontact.com/us/products/1663433>



Crimp contact, contact diameter: 1.6 mm, turned, Socket, contact material: Copper alloy, contact surface: silver-plated, connection cross section: 1.5 mm² ... 1.5 mm², AWG 16

HC-D 25-I-CT-F-Z - Contact insert

1411481

<https://www.phoenixcontact.com/us/products/1411481>



CK1,6-ED-2,50BU AG - Crimp contact

1663446

<https://www.phoenixcontact.com/us/products/1663446>



Crimp contact, contact diameter: 1.6 mm, turned, Socket, contact material: Copper alloy, contact surface: silver-plated, connection cross section: 2.5 mm² ... 2.5 mm², AWG 14

CK1,6-ED-BU-POF - Female contact

1885004

<https://www.phoenixcontact.com/us/products/1885004>



POF fiber optic socket contact, turned, for contact carriers (HC-DD...I-CT.../ HC-M-12-CT-F.../ HC-M-17-CT-F...) of CK1,6-ED... contacts

HC-D 25-I-CT-F-Z - Contact insert

1411481

<https://www.phoenixcontact.com/us/products/1411481>



CK1,6-ED-0,37F AG - Crimp contact

1266249

<https://www.phoenixcontact.com/us/products/1266249>



Crimp contact, contact diameter: 1.6 mm, turned, Socket, contact material: Copper alloy, lead-free, contact surface: silver-plated, connection cross section: 0.14 mm² ... 0.34 mm², AWG 24 ... 22

CK1,6-ED-0,50F AG - Crimp contact

1266252

<https://www.phoenixcontact.com/us/products/1266252>



Crimp contact, contact diameter: 1.6 mm, turned, Socket, contact material: Copper alloy, lead-free, contact surface: silver-plated, connection cross section: 0.5 mm² ... 0.5 mm², AWG 20

HC-D 25-I-CT-F-Z - Contact insert

1411481

<https://www.phoenixcontact.com/us/products/1411481>



CK1,6-ED-0,75F AG - Crimp contact

1266259

<https://www.phoenixcontact.com/us/products/1266259>



Crimp contact, contact diameter: 1.6 mm, turned, Socket, contact material: Copper alloy, lead-free, contact surface: silver-plated, connection cross section: 0.75 mm² ... 0.75 mm², AWG 18

CK1,6-ED-1,00F AG - Crimp contact

1266296

<https://www.phoenixcontact.com/us/products/1266296>



Crimp contact, contact diameter: 1.6 mm, turned, Socket, contact material: Copper alloy, lead-free, contact surface: silver-plated, connection cross section: 1 mm² ... 1 mm², AWG 18

HC-D 25-I-CT-F-Z - Contact insert

1411481

<https://www.phoenixcontact.com/us/products/1411481>



CK1,6-ED-1,50F AG - Crimp contact

1266263

<https://www.phoenixcontact.com/us/products/1266263>



Crimp contact, contact diameter: 1.6 mm, turned, Socket, contact material: Copper alloy, lead-free, contact surface: silver-plated, connection cross section: 1.5 mm² ... 1.5 mm², AWG 16

CK1,6-ED-2,50F AG - Crimp contact

1266295

<https://www.phoenixcontact.com/us/products/1266295>



Crimp contact, contact diameter: 1.6 mm, turned, Socket, contact material: Copper alloy, lead-free, contact surface: silver-plated, connection cross section: 2.5 mm² ... 2.5 mm², AWG 14

HC-D 25-I-CT-F-Z - Contact insert

1411481

<https://www.phoenixcontact.com/us/products/1411481>



CK1,6-ED-0,37BU AU - Crimp contact

1674969

<https://www.phoenixcontact.com/us/products/1674969>



Crimp contact, contact diameter: 1.6 mm, turned, Socket, contact material: Copper alloy, contact surface: gold-plated, connection cross section: 0.14 mm² ... 0.37 mm², AWG 24 ... 22

CK1,6-ED-0,50BU AU - Crimp contact

1674480

<https://www.phoenixcontact.com/us/products/1674480>



Crimp contact, contact diameter: 1.6 mm, turned, Socket, contact material: Copper alloy, contact surface: gold-plated, connection cross section: 0.5 mm² ... 0.5 mm², AWG 20

HC-D 25-I-CT-F-Z - Contact insert

1411481

<https://www.phoenixcontact.com/us/products/1411481>



CK1,6-ED-0,75BU AU - Crimp contact

1672440

<https://www.phoenixcontact.com/us/products/1672440>



Crimp contact, contact diameter: 1.6 mm, turned, Socket, contact material: Copper alloy, contact surface: gold-plated, connection cross section: 0.75 mm² ... 0.75 mm², AWG 18

CK1,6-ED-1,00BU AU - Crimp contact

1674943

<https://www.phoenixcontact.com/us/products/1674943>



Crimp contact, contact diameter: 1.6 mm, turned, Socket, contact material: Copper alloy, contact surface: gold-plated, connection cross section: 1 mm² ... 1 mm², AWG 18

HC-D 25-I-CT-F-Z - Contact insert

1411481

<https://www.phoenixcontact.com/us/products/1411481>



CK1,6-ED-1,50BU AU - Crimp contact

1674930

<https://www.phoenixcontact.com/us/products/1674930>



Crimp contact, contact diameter: 1.6 mm, turned, Socket, contact material: Copper alloy, contact surface: gold-plated, connection cross section: 1.5 mm² ... 1.5 mm², AWG 16

CK1,6-ED-2,50BU AU - Crimp contact

1674985

<https://www.phoenixcontact.com/us/products/1674985>



Crimp contact, contact diameter: 1.6 mm, turned, Socket, contact material: Copper alloy, contact surface: gold-plated, connection cross section: 2.5 mm² ... 2.5 mm², AWG 14

HC-D 25-I-CT-F-Z - Contact insert



1411481

<https://www.phoenixcontact.com/us/products/1411481>

CK1,6-ER-1,00BU OIC AG - Crimp contact

1004362

<https://www.phoenixcontact.com/us/products/1004362>



Crimp contact, contact diameter: 1.6 mm, rolled, Socket, contact material: Cu alloy, nickel-plated, contact surface: silver-plated, connection cross section: 0.34 mm² ... 1 mm², AWG 22 ... 17

CK1,6-ER-2,50BU OIC AG - Crimp contact

1004366

<https://www.phoenixcontact.com/us/products/1004366>



Crimp contact, contact diameter: 1.6 mm, rolled, Socket, contact material: Cu alloy, nickel-plated, contact surface: silver-plated, connection cross section: 1.5 mm² ... 2.5 mm², AWG 16 ... 14

HC-D 25-I-CT-F-Z - Contact insert

1411481

<https://www.phoenixcontact.com/us/products/1411481>



CK1,6-BR-1,00BU OIC AG - Crimp contact

1004381

<https://www.phoenixcontact.com/us/products/1004381>



Crimp contact, contact diameter: 1.6 mm, rolled, Socket, contact material: Cu alloy, nickel-plated, contact surface: silver-plated, connection cross section: 0.34 mm² ... 1 mm², AWG 22 ... 17, Taped products

CK1,6-BR-2,50BU OIC AG - Crimp contact

1004383

<https://www.phoenixcontact.com/us/products/1004383>



Crimp contact, contact diameter: 1.6 mm, rolled, Socket, contact material: Cu alloy, nickel-plated, contact surface: silver-plated, connection cross section: 1.5 mm² ... 2.5 mm², AWG 16 ... 14, Taped products

HC-D 25-I-CT-F-Z - Contact insert

1411481

<https://www.phoenixcontact.com/us/products/1411481>



HC-D 25-I-CT-M-Z - Contact insert

1411478

<https://www.phoenixcontact.com/us/products/1411478>



HEAVYCON pin insert, D25 series, 25-pos., crimp connection, with special printing (row C pos. 1 is printed with the letter Z)

Phoenix Contact 2023 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com