




Color: ■ light gray

Similar to illustration

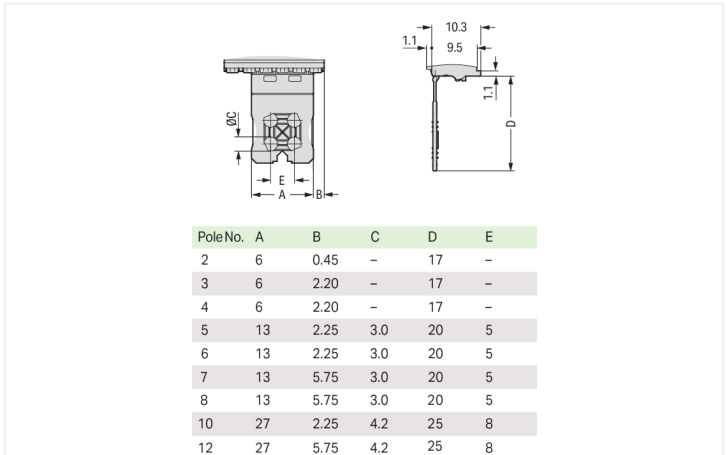

Dimensions in mm

Physical data

Pin spacing	3.5 mm / 0.138 inches
Width	27 mm

Material data

Note (material data)	Information on material specifications can be found here
Color	light gray
Flammability class per UL94	V0
Fire load	0.015 MJ
Weight	0.5 g

Commercial data

Product Group	26 (picoMAX Connectors)
PU (SPU)	100 (25) pcs
Packaging type	Box
Country of origin	DE
GTIN	4050821162766
Customs tariff number	85389099990

Product classification

UNSPSC	39121702
eCl@ss 10.0	27-14-11-92
eCl@ss 9.0	27-14-11-92
ETIM 9.0	EC002848
ETIM 8.0	EC002848
ECCN	NO US CLASSIFICATION



Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

Downloads

Environmental Product Compliance

Compliance Search

Environmental Product Compliance 2091-1603

↓


Documentation

Additional Information

Technical Section	03.04.2019	pdf 2027.26 KB	↓
-------------------	------------	-------------------	---

Installation Notes

Strain relief

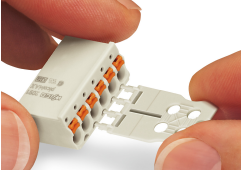

Gripping plates are suitable for factory and field assembly.