



RADIAL[®]
MULTI-CONTACT CONNECTORS

TECHNICAL DATA SHEET



619 069 002

Series
BPX

SIZE 8 CONCENTRIC TWINAX SOCKET CONTACT
FOR MIL-C-17/176-00002 CABLE

Issue:
06 NOV. 2003

Page
1/1

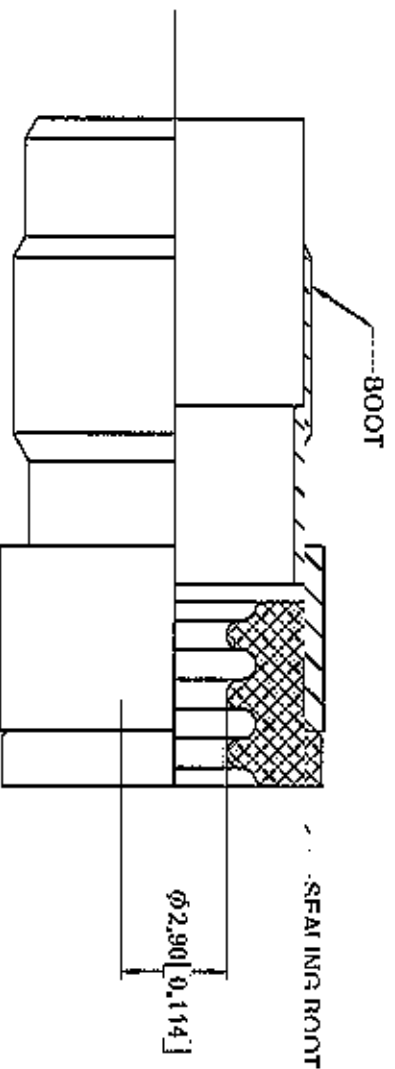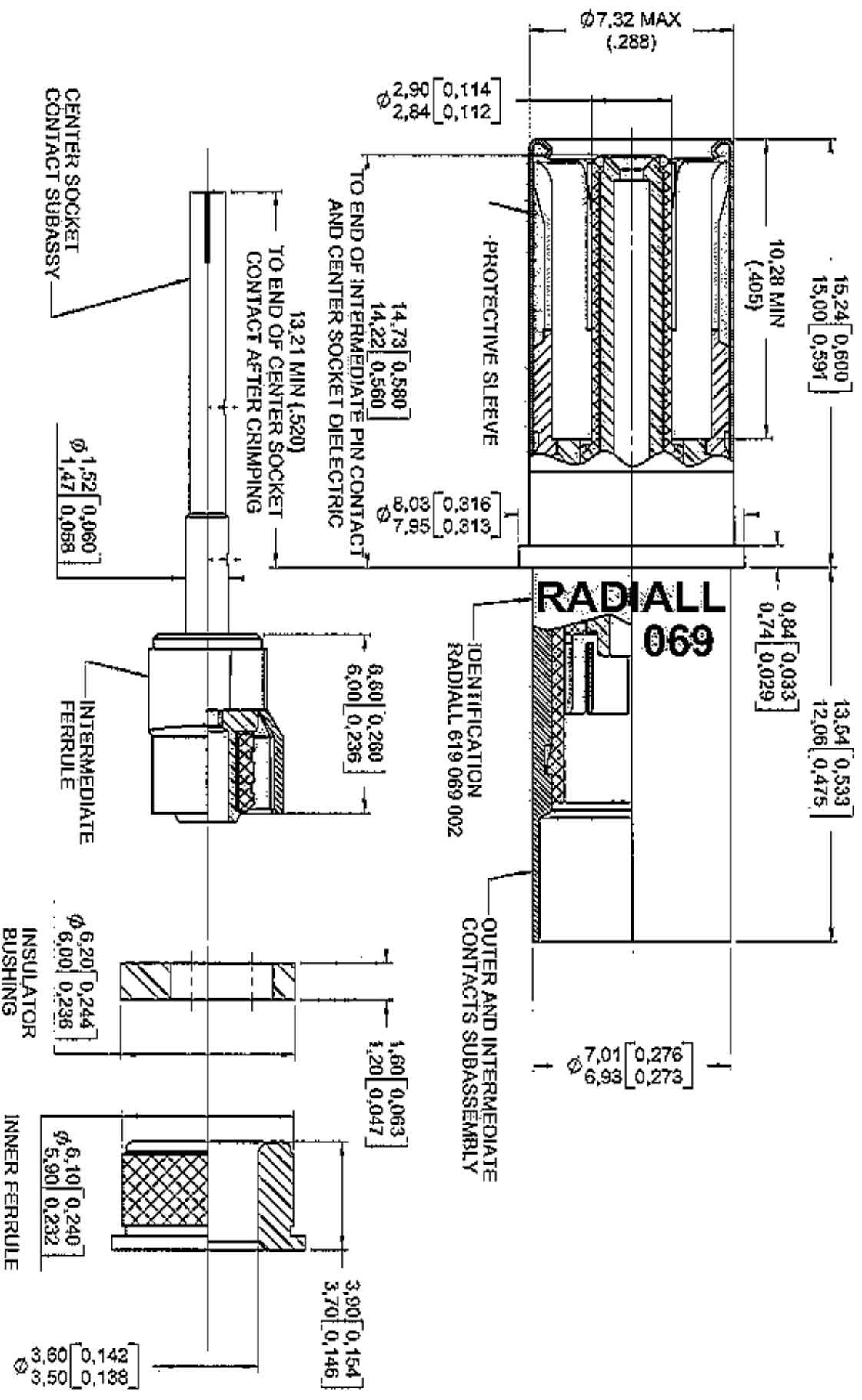

MATERIALS:

- OUTER AND CENTER CONTACT: BERYLLIUM COPPER ALLOY PER QQ-C-530 HEAT TREATED ANNEALED ON CRIMP BARREL
- INTERMEDIATE CONTACT: BERYLLIUM COPPER ALLOY PER QQ-C-530 HEAT TREATED
- FERRULE AND INNER FERRULE: BRASS PER QQ-B-626
- INTERMEDIATE DIELECTRIC AND INSULATOR BUSHING: PTFE
- CENTER DIELECTRIC: ULTEM
- PROTECTIVE SLEEVE: STAINLESS STEEL AISI305
- BOOT: THERMOPLASTIC PER MIL-M-14
- SEALING BOOT: FLUOROSILICONE ELASTOMER PER MIL-R-25988 OR ZZ-R-765

FINISHES (ALL METAL PARTS)

- GOLD PER MIL-C-45204, TYPE II, GRADE C, CLASS 1 OVER NICKEL PER QQ-N-290, CLASS 2

WIRING INSTRUCTIONS: SEE RP08820

DIMENSIONS : mm (inch) -



CREATION	Issue	Revisions	Name	Approved
PEN: M030400043A				
NOM: LEGENDRE				
DATE: 06/11/03				
APPR: MACABRE				

619069002EN

4112_9311

This information is given as an indication. In the continual goal to improve our products, we reserve the right to make any modifications judged necessary.